


平压花姆指螺帽 · DIN 653

24770.0356

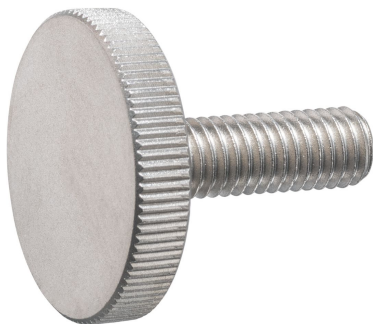

产品描述

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

所有滚花螺丝是整体都有螺纹的一体成型制品 (DIN-代号 A)。

材质

- 不锈钢 1.4305, 钝化喷砂

更多信息


注意事项

根据 DIN 规范, 压花的间距和深度也不同。

更多产品

- 高压花的手转螺丝, DIN 464

图面

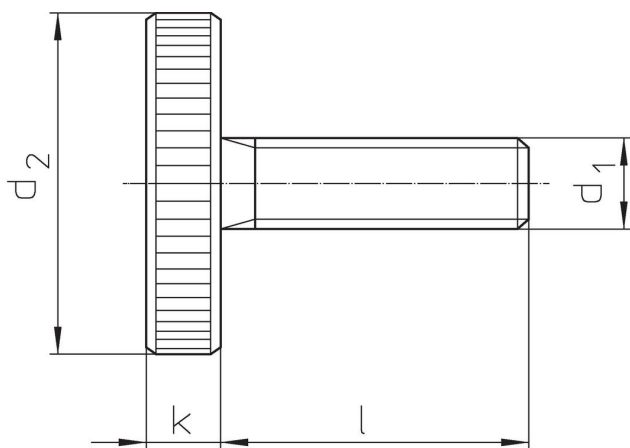

订单信息

d ₁	尺寸 l [mm]	d ₂	k	重量 [g]	品号
不锈钢					
M8	25	30	6	39	24770.0356

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单。

不含 65 号提案物质

不包括 65 号提案物质

<https://www.P65Warnings.ca.gov/>

不含冲突矿物

„本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质, 例如钽、锡、金或钨。