

## 平压花姆指螺帽 · DIN 653

24770.0538



### 产品描述

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

所有滚花螺丝是整体都有螺纹的一体成型制品 (DIN-代号 A)。

### 材质

- Steel, zinc-plated by galvanization, quality 5.8

### 更多信息


#### 注意事项

根据 DIN 规范，压花的间距和深度也不同。

#### 更多产品

- 高压花的手转螺丝, DIN 464

### 图面

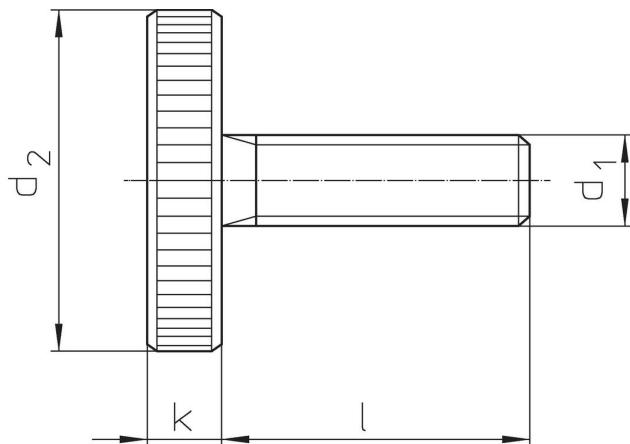

### 订单信息

	尺寸					品号		
	d <sub>1</sub>		l		d <sub>2</sub>	k		
	[mm]						[g]	
钢								
	M6		25		24	5	20	24770.0538

### 遵守

#### 符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

#### 不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单。

#### 不含 65 号提案物质

不包括 65 号提案物质

<https://www.P65Warnings.ca.gov/>

#### 不含冲突矿物

本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质，例如钽、锡、金或钨。