

定位珠螺丝 · 有头

EH 22710.



产品描述

亦适用于固夹、上紧或支撑不完全平行的表面。
最大荷载传递因为可移动的球体。

材质

珠子

- 轴承钢，硬化
- 不锈钢，硬化

螺丝

- 钢，热处理， $1200 \pm 100 \text{ N/mm}^2$
- 不锈钢 1.4305

更多信息

注意事项

珠子无防止旋转功能。
特殊的样式欢迎洽询。


参考

需求的螺纹锁，请参阅附录 - 技术数据 -

更多产品

- 定位珠螺丝，有头，球防止回转

图面

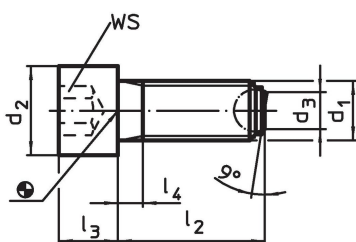

订单信息

d ₁	l ₂ ~	d ₂	尺寸 [mm]			球直径	WS [mm]	静态荷重能力 ¹⁾ max. [kN]	重量 [g]	品号
			d ₃	l ₃	l ₄					
平面 珠子，平面 表面 (相片2)，热处理钢										
M 6	20	10	3,2	6	3,0	4,0	5	9	6,1	22710.0562
M 6	30	10	3,2	6	3,0	4,0	5	9	7,8	22710.0564
M 6	40	10	3,2	6	16,0	4,0	5	9	9,9	22710.0566
M 8	20	13	4,5	8	3,5	5,5	6	15	12,0	22710.0582
M 8	35	13	4,5	8	3,5	5,5	6	15	17,0	22710.0584
M 8	50	13	4,5	8	22,0	5,5	6	15	23,0	22710.0586
M10	25	16	6,0	10	4,5	7,0	8	20	24,0	22710.0602
M10	40	16	6,0	10	4,5	7,0	8	20	32,0	22710.0604
M10	60	16	6,0	10	28,0	7,0	8	20	44,0	22710.0606
M12	30	18	7,2	12	5,0	8,5	10	30	38,0	22710.0622
M12	50	18	7,2	12	5,0	8,5	10	30	52,0	22710.0624
M12	80	18	7,2	12	44,0	8,5	10	30	80,0	22710.0626
M16	40	24	10,7	16	6,0	12,0	14	60	95,0	22710.0662
M16	60	24	10,7	16	6,0	12,0	14	60	121,0	22710.0664
M16	80	24	10,7	16	36,0	12,0	14	60	153,0	22710.0666
M20	50	30	13,5	20	7,5	15,0	17	90	185,0	22710.0702
M20	80	30	13,5	20	28,0	15,0	17	90	254,0	22710.0704
M20	100	30	13,5	20	48,0	15,0	17	90	304,0	22710.0706
M24	60	36	15,8	24	9,0	18,0	19	120	323,0	22710.0742
M24	90	36	15,8	24	30,0	18,0	19	120	424,0	22710.0744
M24	120	36	15,8	24	60,0	18,0	19	120	526,0	22710.0746
平面 珠子，平面 表面 (相片2)，不锈钢										
M 6	20	10	3,2	6	3,0	4,0	5	9	6,1	22710.0832
M 6	30	10	3,2	6	3,0	4,0	5	9	7,8	22710.0834
M 6	40	10	3,2	6	16,0	4,0	5	9	9,9	22710.0836
M 8	20	13	4,5	8	3,5	5,5	6	15	12,0	22710.0842

¹⁾*荷重能力报告书不适用于不锈钢

d ₁	l ₂ ~	d ₂	尺寸			球直径	WS [mm]	静态荷重能力 ¹⁾ max. [kN]	📏 [g]	品号
			d ₃	l ₃	l ₄					
			[mm]							
M 8	35	13	4,5	8	3,5	5,5	6	15	17,0	22710.0844
M 8	50	13	4,5	8	22,0	5,5	6	15	23,0	22710.0846
M10	25	16	6,0	10	4,5	7,0	8	20	24,0	22710.0852
M10	40	16	6,0	10	4,5	7,0	8	20	32,0	22710.0854
M10	60	16	6,0	10	28,0	7,0	8	20	44,0	22710.0856
M12	30	18	7,2	12	5,0	8,5	10	30	38,0	22710.0862
M12	50	18	7,2	12	5,0	8,5	10	30	52,0	22710.0864
M12	80	18	7,2	12	44,0	8,5	10	30	80,0	22710.0866
M16	40	24	10,7	16	6,0	12,0	14	60	95,0	22710.0872
M16	60	24	10,7	16	6,0	12,0	14	60	121,0	22710.0874
M16	80	24	10,7	16	36,0	12,0	14	60	153,0	22710.0876
肋纹面, 热处理钢										
M 8	20	13	4,5	8	3,5	5,5	6	15	12,0	22710.0892
M 8	35	13	4,5	8	3,5	5,5	6	15	17,0	22710.0894
M 8	50	13	4,5	8	22,0	5,5	6	15	23,0	22710.0896
M10	25	16	6,0	10	4,5	7,0	8	20	24,0	22710.0902
M10	40	16	6,0	10	4,5	7,0	8	20	31,0	22710.0904
M10	60	16	6,0	10	28,0	7,0	8	20	44,0	22710.0906
M12	30	18	7,2	12	5,0	8,5	10	30	38,0	22710.0922
M12	50	18	7,2	12	5,0	8,5	10	30	52,0	22710.0924
M12	80	18	7,2	12	44,0	8,5	10	30	80,0	22710.0926
M16	40	24	10,7	16	6,0	12,0	14	60	93,0	22710.0962
M16	60	24	10,7	16	6,0	12,0	14	60	121,0	22710.0964
M16	80	24	10,7	16	36,0	12,0	14	60	152,0	22710.0966
M20	50	30	13,5	20	7,5	15,0	17	90	184,0	22710.0972
M20	80	30	13,5	20	28,0	15,0	17	90	255,0	22710.0974
M20	100	30	13,5	20	48,0	15,0	17	90	303,0	22710.0976
M24	60	36	15,8	24	9,0	18,0	19	120	324,0	22710.0982
M24	90	36	15,8	24	30,0	18,0	19	120	426,0	22710.0984
M24	120	36	15,8	24	60,0	18,0	19	120	528,0	22710.0986

¹⁾ *荷重能力报告书不适用于不锈钢

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单。

不含 65 号提案物质

不包括 65 号提案物质

<https://www.P65Warnings.ca.gov/>

不含冲突矿物

„本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质，例如钽、锡、金或钨。