

星型把手 · DIN 6336 不锈钢 压铸
EH 24661.



产品描述

These star grips are manufactured according to DIN 6336.

材质

把手

- 不锈钢 A2, 雾面喷砂


图面





图片 1




图片 2

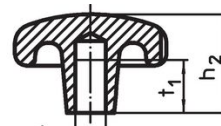

图片 3

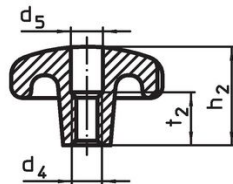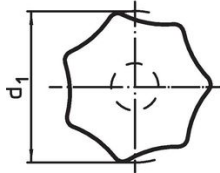

图片 4

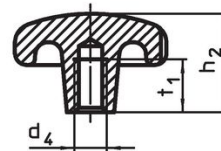

图片 5

订单信息

d ₁	d ₂	d ₄	d ₅	尺寸					[g]	品号	
				h ₁	h ₂	h ₃	t ₁ min	t ₂			
[mm]											
未加工, 型式 A – 相片 1											
32	12	–	–	21	–	10	–	–	–	56	24661.0032
40	14	–	–	26	–	13	–	–	–	85	24661.0040
50	18	–	–	34	–	17	–	–	–	181	24661.0050
63	20	–	–	42	–	21	–	–	–	319	24661.0063
有母牙 螺纹, 钻孔, 型式 D – 相片 4											
32	12	M 6	6,4	–	20	–	–	–	10	52	24661.0332
40	14	M 8	8,4	–	25	–	–	–	13	75	24661.0340
50	18	M10	10,5	–	32	–	–	–	16	149	24661.0350
63	20	M12	13,0	–	40	–	–	–	20	279	24661.0363
有盲孔, 母牙, 型式 E – 相片 5											
32	12	M 6	–	–	20	–	12	–	–	53	24661.0432
40	14	M 8	–	–	25	–	15	–	–	77	24661.0440
50	18	M10	–	–	32	–	18	–	–	158	24661.0450
63	20	M12	–	–	40	–	22	–	–	296	24661.0463

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单.

不含 65 号提案物质

不包括 65 号提案物质

<https://www.P65Warnings.ca.gov/>

不含冲突矿物

„本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质，例如钽、锡、金或钨。