

## 挖地螺丝和掌形把手 · DIN 6335 塑料

EH 24730.



### 产品描述

#### 材质

##### 把手

- 热固性塑胶 (PF 31), 黑色 (接近色号 RAL 9005)

##### 螺丝


- 钢, 镀锌
- 不锈钢 A2

#### 更多信息

##### 注意事项

特殊制作, 例如: 不同的长度或螺杆, 材料是黄铜, 不锈钢, 欢迎洽询。

### 图面

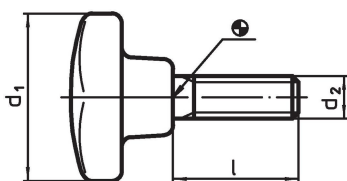

### 订单信息

d <sub>1</sub>	尺寸		l	max. [°C]	[g]	品号
	d <sub>2</sub> [mm]					
底部 / 侧边联结, 钢						
25	M 5		10	110	6,6	<a href="#">24730.0051</a>
25	M 5		15	110	7,0	<a href="#">24730.0053</a>
25	M 5		20	110	7,5	<a href="#">24730.0056</a>
25	M 5		25	110	8,1	<a href="#">24730.0058</a>
25	M 5		30	110	8,9	<a href="#">24730.0059</a>
32	M 6		15	110	11,0	<a href="#">24730.0101</a>
32	M 6		20	110	13,0	<a href="#">24730.0104</a>
32	M 6		25	110	13,0	<a href="#">24730.0106</a>
32	M 6		30	110	14,0	<a href="#">24730.0107</a>
32	M 6		40	110	16,0	<a href="#">24730.0110</a>
40	M 8		20	110	24,0	<a href="#">24730.0152</a>
40	M 8		25	110	25,0	<a href="#">24730.0154</a>
40	M 8		30	110	26,0	<a href="#">24730.0155</a>
40	M 8		40	110	30,0	<a href="#">24730.0158</a>
40	M 8		50	110	32,0	<a href="#">24730.0160</a>
50	M10		25	110	41,0	<a href="#">24730.0202</a>
50	M10		30	110	48,0	<a href="#">24730.0203</a>
50	M10		40	110	51,0	<a href="#">24730.0206</a>
50	M10		50	110	56,0	<a href="#">24730.0208</a>
50	M10		60	110	68,0	<a href="#">24730.0209</a>
63	M12		30	110	99,0	<a href="#">24730.0251</a>
63	M12		40	110	93,0	<a href="#">24730.0254</a>
63	M12		50	110	99,0	<a href="#">24730.0256</a>
63	M12		60	110	105,0	<a href="#">24730.0257</a>
63	M12		80	110	112,0	<a href="#">24730.0260</a>
80	M16		40	110	198,0	<a href="#">24730.0302</a>
80	M16		50	110	214,0	<a href="#">24730.0304</a>
80	M16		60	110	219,0	<a href="#">24730.0305</a>
80	M16		80	110	251,0	<a href="#">24730.0308</a>

d <sub>1</sub>	尺寸		max. [°C]	[g]	品号
	d <sub>2</sub> [mm]	l			
底部 / 侧边联结, 不锈钢					
25	M 5	10	110	6,6	24730.1051
25	M 5	15	110	7,0	24730.1053
25	M 5	20	110	7,5	24730.1056
25	M 5	25	110	8,1	24730.1058
25	M 5	30	110	8,9	24730.1059
32	M 6	15	110	11,0	24730.1101
32	M 6	20	110	13,0	24730.1104
32	M 6	25	110	13,0	24730.1106
32	M 6	30	110	14,0	24730.1107
32	M 6	40	110	16,0	24730.1110
40	M 8	20	110	24,0	24730.1152
40	M 8	25	110	25,0	24730.1154
40	M 8	30	110	26,0	24730.1155
40	M 8	40	110	30,0	24730.1158
40	M 8	50	110	32,0	24730.1160
50	M10	25	110	41,0	24730.1202
50	M10	30	110	48,0	24730.1203
50	M10	40	110	51,0	24730.1206
50	M10	50	110	56,0	24730.1208
50	M10	60	110	68,0	24730.1209
63	M12	30	110	99,0	24730.1251
63	M12	40	110	93,0	24730.1254
63	M12	50	110	99,0	24730.1256
63	M12	60	110	105,0	24730.1257
63	M12	80	110	112,0	24730.1260
80	M16	40	110	198,0	24730.1302
80	M16	50	110	214,0	24730.1304
80	M16	60	110	219,0	24730.1305
80	M16	80	110	251,0	24730.1308

## 遵守

### 符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

### 不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单.

### 不含 65 号提案物质

不包括 65 号提案物质

<https://www.P65Warnings.ca.gov/>

### 不含冲突矿物

„本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质，例如钽、锡、金或钨。