

固定轴环·带有感应器的接头
EH 25070.



产品描述

夹紧环提供有紧固作用的传感器，开关等。普遍适用性，即作为一个活塞杆的限位开关。
夹紧圈由不锈钢制成具有很强的夹力。

材质


螺丝

- 不锈钢

轴环

- 不锈钢 1.4021

图面


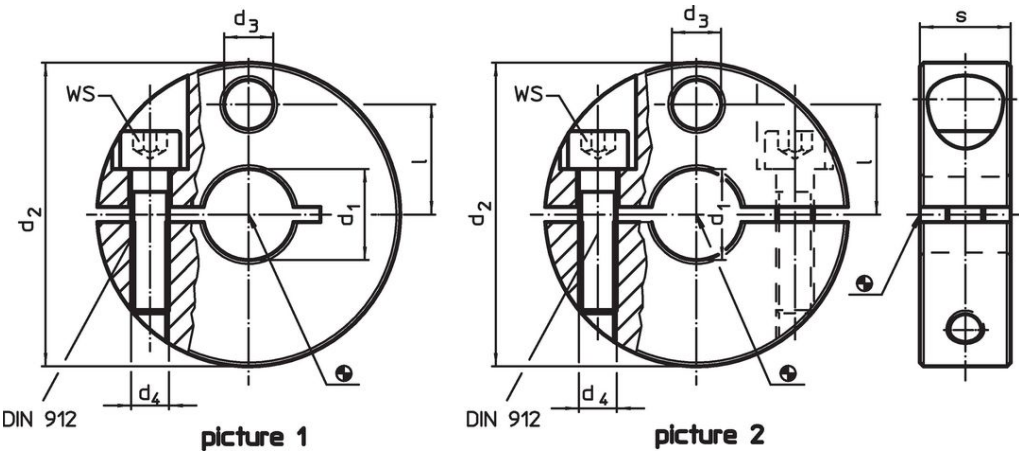


订单信息

d ₁ H8		d ₂ -0,5	尺寸		d ₄	l	s	WS		品号
			[mm]					[mm]	[g]	
有槽沟 – 相片 1										
10		40	6,5	M5	14,5	12	4	99		25070.0010
12		40	6,5	M5	14,5	12	4	93		25070.0012
14		45	9,0	M6	16,5	13	5	125		25070.0014
15		45	9,0	M6	16,5	13	5	122		25070.0015
16		45	9,0	M6	16,5	13	5	120		25070.0016
18		50	9,0	M6	18,5	13	5	151		25070.0018
20		50	9,0	M6	18,5	13	5	144		25070.0020
22		65	13,0	M8	23,5	18	6	359		25070.0022
24		65	13,0	M8	23,5	18	6	349		25070.0024
25		65	13,0	M8	23,5	18	6	345		25070.0025
30		75	13,0	M8	27,0	20	6	506		25070.0030
32		80	13,0	M8	30,0	20	6	588		25070.0032
35		80	13,0	M8	30,0	20	6	566		25070.0035
分割的 – 相片 2										
10		40	6,5	M5	14,5	12	4	94		25070.0110
12		40	6,5	M5	14,5	12	4	90		25070.0112
14		45	9,0	M6	16,5	13	5	114		25070.0114
15		45	9,0	M6	16,5	13	5	112		25070.0115
16		45	9,0	M6	16,5	13	5	110		25070.0116
18		50	9,0	M6	18,5	13	5	142		25070.0118
20		50	9,0	M6	18,5	13	5	139		25070.0120
22		65	13,0	M8	23,5	18	6	341		25070.0122
24		65	13,0	M8	23,5	18	6	330		25070.0124

尺寸						WS		品号
d ₁ H8	d ₂ -0,5	d ₃	d ₄	l	s			
[mm]						[mm]	[g]	
25	65	13,0	M8	23,5	18	6	330	25070.0125
30	75	13,0	M8	27,0	20	6	488	25070.0130
32	80	13,0	M8	30,0	20	6	564	25070.0132
35	80	13,0	M8	30,0	20	6	542	25070.0135

应用范例

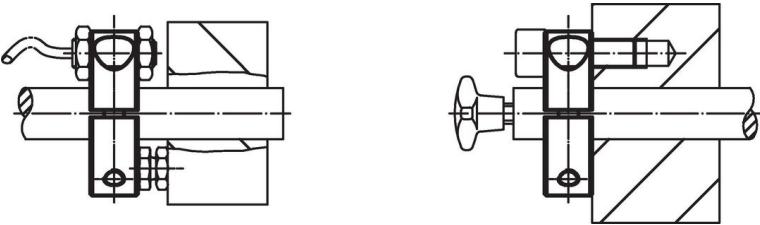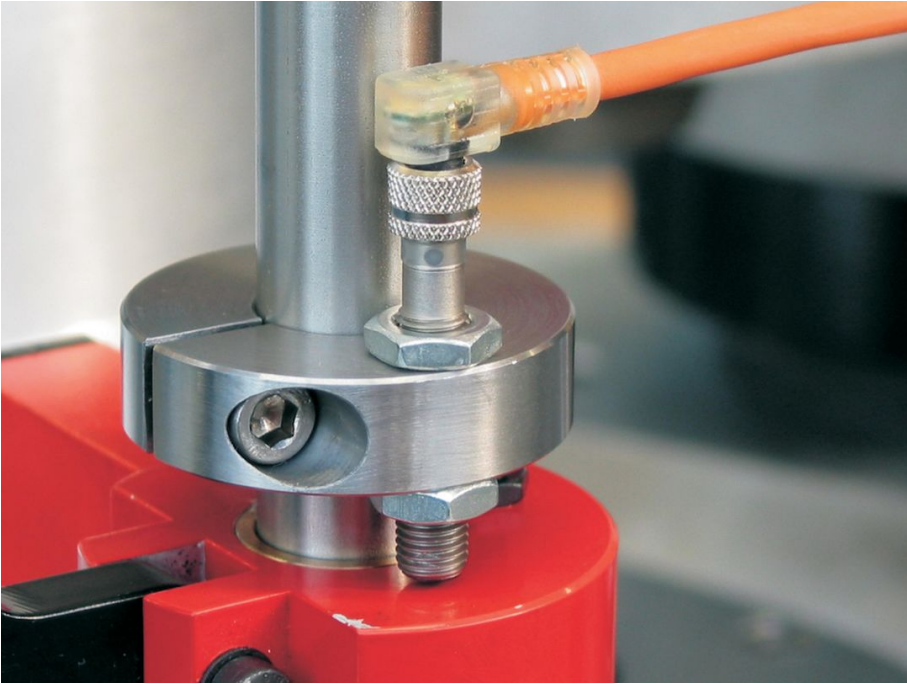

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物质

不含超过 0.1% w/w 的 SVHC 物质 - 截至 2024 年 6 月 27 日的 SVHC 清单.

不含 65 号提案物质

不包括 65 号提案物质
<https://www.P65Warnings.ca.gov/>

不含冲突矿物

„本产品不含来自刚果民主共和国或邻近国家的任何被指定为“冲突矿物”的物质，例如钽、锡、金或钨。