

## Koule • kovová provedení dle DIN 319

EH 24561.



## Popis produktu

## Materiál


- Ocel, leštěná, čistá
- Nerez 1.4305, matná
- Hliník, leštěný

## Další informace

## Poznámky

Rozšíření DIN 319 provedení C o kovové varianty.


## Výkres s rozměry

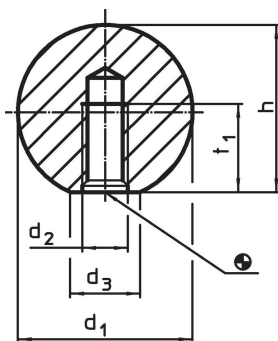

## Informace pro objednání

d <sub>1</sub>	d <sub>2</sub>	Rozměry		t <sub>1</sub> min.	[g]	Obj. č.
		d <sub>3</sub> ~ [mm]	h ~			
<b>Ocel</b>						
16	M 4	8	15,0	7,0	16	<a href="#">24561.0016</a>
20	M 5	12	18,0	9,0	26	<a href="#">24561.0020</a>
25	M 6	15	22,5	11,0	58	<a href="#">24561.0025</a>
32	M 8	18	29,0	14,5	116	<a href="#">24561.0032</a>
40	M10	22	37,0	18,0	241	<a href="#">24561.0040</a>
50	M12	27	46,0	21,0	475	<a href="#">24561.0050</a>
<b>Nerez</b>						
16	M 4	8	15,0	7,0	16	<a href="#">24561.0216</a>
20	M 5	12	18,0	9,0	26	<a href="#">24561.0220</a>
25	M 6	15	22,5	11,0	58	<a href="#">24561.0225</a>
32	M 8	18	29,0	14,5	116	<a href="#">24561.0232</a>
40	M10	22	37,0	18,0	241	<a href="#">24561.0240</a>
<b>Hliník Al</b>						
16	M 4	8	15,0	7,0	16	<a href="#">24561.0116</a>
20	M 5	12	18,0	9,0	26	<a href="#">24561.0120</a>
25	M 6	15	22,5	11,0	58	<a href="#">24561.0125</a>
32	M 8	18	29,0	14,5	116	<a href="#">24561.0132</a>
40	M10	22	37,0	18,0	241	<a href="#">24561.0140</a>
50	M12	27	46,0	21,0	475	<a href="#">24561.0150</a>

## Příklad použití

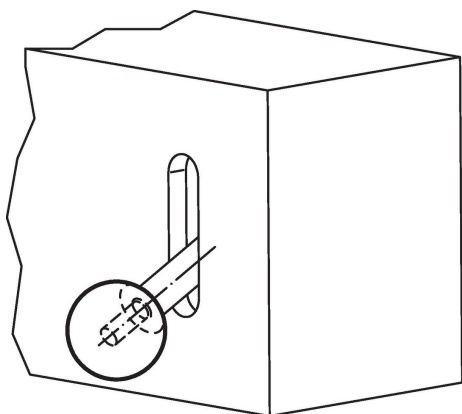

## Shoda

Pro podrobné informace o shodě vyberte, prosím, požadované číslo výrobku.