

## Panty • elongated on one side EH 25165.



### Popis produktu

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

### Materiál


#### Základní těleso

- Nerez 1.4301
- Ocel, zinkovaná, pasivovaná

#### Osa

- Nerez 1.4301


### Výkres s rozměry

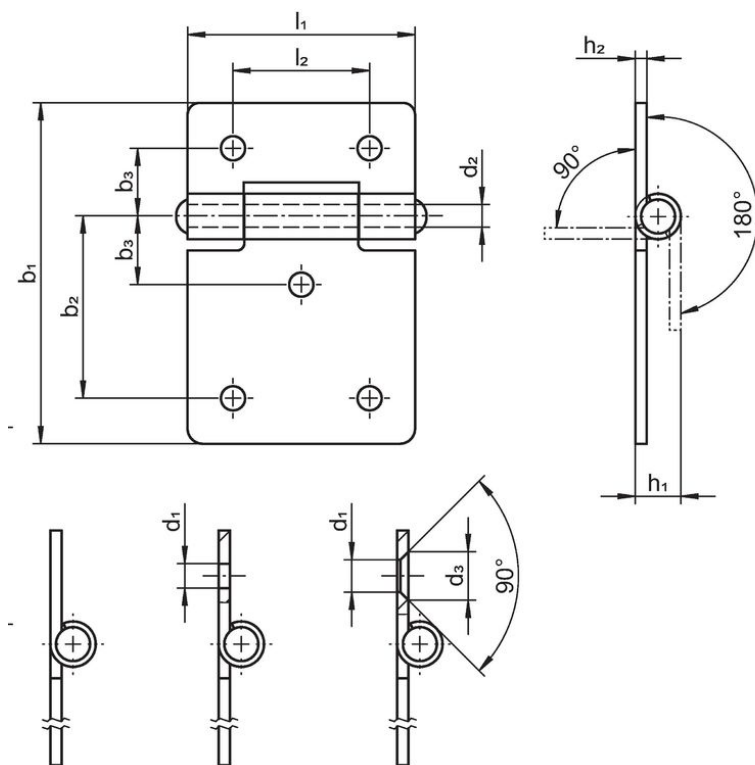

Obr. 1

Obr. 2

Obr. 3

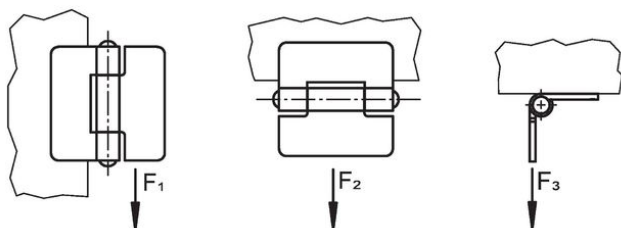

Informace pro objednání

b <sub>1</sub>	l <sub>1</sub>	b <sub>2</sub>	b <sub>3</sub>	Rozměry						Přidržná síla			[g]	Obj. č.	
				d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	l <sub>2</sub>	F <sub>1</sub>	F <sub>2</sub>	F <sub>3</sub>			
				[mm]						[N]					
<b>without bores – obrázek 1, Nerez</b>															
45	30	–	–	–	3	–	6	1,5	–	700	500	450	20	25165.0035	
60	40	–	–	–	4	–	8	2,0	–	1200	1000	1000	47	25165.0055	
75	50	–	–	–	6	–	10	2,0	–	1600	2000	1000	81	25165.0070	
90	60	–	–	–	6	–	10	2,0	–	1100	2500	1000	111	25165.0080	
<b>with bores – obrázek 2, Nerez</b>															
45	30	24,0	9,0	3,2	3	–	6	1,5	18	700	500	450	19	25165.0135	
60	40	32,5	12,5	4,2	4	–	8	2,0	18	1200	1000	1000	45	25165.0155	
75	50	40,0	15,0	5,2	6	–	10	2,0	30	1600	2000	1000	79	25165.0170	
90	60	48,0	18,0	5,2	6	–	10	2,0	36	1100	2500	1000	108	25165.0180	
<b>with bores – obrázek 2, Ocel</b>															
45	30	24,0	9,0	3,2	3	–	6	1,5	18	700	500	450	19	25165.1035	
60	40	32,5	12,5	4,2	4	–	8	2,0	25	1200	1000	1000	45	25165.1055	
75	50	40,0	15,0	5,2	6	–	10	2,0	30	1600	2000	1000	79	25165.1070	
90	60	48,0	18,0	5,2	6	–	10	2,0	36	1100	2500	1000	108	25165.1080	
<b>with bores for countersunk screws – obrázek 3, Nerez</b>															
45	30	24,0	9,0	4,0	3	6,4	6	1,5	18	700	500	450	19	25165.0235	
60	40	32,5	12,5	5,0	4	8,3	8	2,0	25	1200	1000	1000	45	25165.0255	
75	50	40,0	15,0	5,0	6	8,3	10	2,0	30	1600	2000	1000	79	25165.0270	
90	60	48,0	18,0	5,0	6	8,3	10	2,0	36	1100	2500	1000	108	25165.0280	
<b>with bores for countersunk screws – obrázek 3, Ocel</b>															
45	30	24,0	9,0	4,0	3	6,4	6	1,5	18	700	500	450	19	25165.2035	
60	40	32,5	12,5	5,0	4	8,3	8	2,0	25	1200	1000	1000	45	25165.2055	
75	50	40,0	15,0	5,0	6	8,3	10	2,0	30	1600	2000	1000	79	25165.2070	
90	60	48,0	18,0	5,0	6	8,3	10	2,0	36	1100	2500	1000	108	25165.2080	

Shoda

Vyhovuje RoHS

V souladu se směrnicí 2011/65/EU a směrnicí 2015/863.

Neobsahuje látky SVHC

Žádné látky SVHC s obsahem vyšším než 0,1% hm. - seznam SVHC k 27.06.2024.

Neobsahuje látky Proposition 65

Neobsahuje látky Proposition 65.

<https://www.P65Warnings.ca.gov/>

Bez konfliktních minerálů

Tento produkt neobsahuje žádné látky označené jako "konfliktní minerály" jako je tantal, cín, zlato nebo wolfram z Demokratické republiky Kongo nebo sousedních zemí.