

Bolas • metálicas similares a DIN 319

EH 24561.



Descripción del Producto

Material


- Acero, pulido, brillante
- Acero inoxidable 1.4305, mate
- Aluminio, pulido

Más información

Notas

Extensión de gama del DIN 319 Forma C con versiones metálicas.


Dibujo

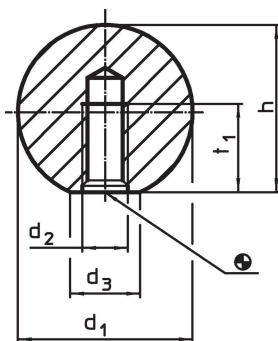

Información para el pedido

d ₁	d ₂	Dimensiones		t ₁ min.	[g]	Referencia
		d ₃ ~ [mm]	h ~			
Acero						
16	M 4	8	15,0	7,0	16	24561.0016
20	M 5	12	18,0	9,0	26	24561.0020
25	M 6	15	22,5	11,0	58	24561.0025
32	M 8	18	29,0	14,5	116	24561.0032
40	M10	22	37,0	18,0	241	24561.0040
50	M12	27	46,0	21,0	475	24561.0050
Acero inoxidable						
16	M 4	8	15,0	7,0	16	24561.0216
20	M 5	12	18,0	9,0	26	24561.0220
25	M 6	15	22,5	11,0	58	24561.0225
32	M 8	18	29,0	14,5	116	24561.0232
40	M10	22	37,0	18,0	241	24561.0240
Aluminio Al						
16	M 4	8	15,0	7,0	16	24561.0116
20	M 5	12	18,0	9,0	26	24561.0120
25	M 6	15	22,5	11,0	58	24561.0125
32	M 8	18	29,0	14,5	116	24561.0132
40	M10	22	37,0	18,0	241	24561.0140
50	M12	27	46,0	21,0	475	24561.0150

Ejemplo de aplicación

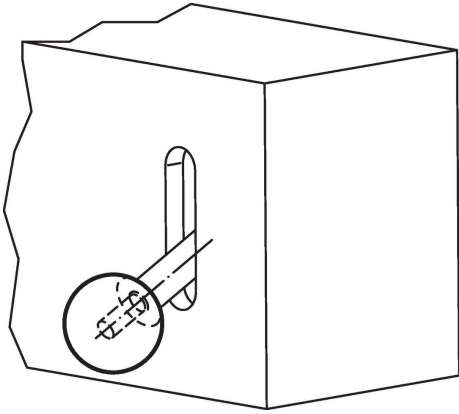

Cumplimiento

Para obtener información detallada sobre el cumplimiento, seleccione el número de artículo deseado.