

Tuercas Moleteadas • plástico

EH 24820.



Descripción del Producto

Material


Casquillo

- Acero, cincado por galvanización
- Acero inoxidable 1.4305

Empuñadura

- Termoplástico PA, negro


Dibujo

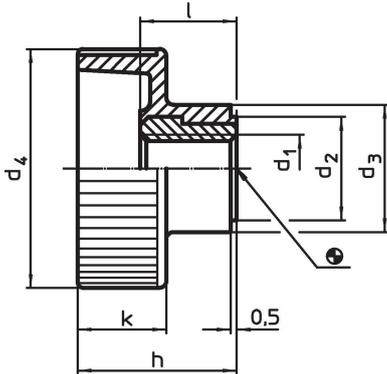

Información para el pedido

Dimensiones							Temperatura		Peso [g]	Referencia
d ₁	d ₂	d ₃	d ₄	h	k	l	mín. [°C]	máx. [°C]		
Acero										
M 4	9	12	19	14,0	8,0	9,0	-30	80	4,5	24820.0004
M 5	9	12	19	14,0	8,0	9,0	-30	80	4,0	24820.0005
M 6	12	14	24	16,5	9,5	10,5	-30	80	7,0	24820.0006
M 8	14	16	30	19,5	11,0	11,5	-30	80	10,0	24820.0008
M10	16	18	36	22,5	12,5	14,0	-30	80	15,0	24820.0010
Acero inoxidable										
M 5	9	12	19	14,0	8,0	9,0	-30	80	4,0	24820.0205
M 6	12	14	24	16,5	9,5	10,5	-30	80	7,0	24820.0206
M 8	14	16	30	19,5	11,0	11,5	-30	80	10,0	24820.0208

Ejemplo de aplicación

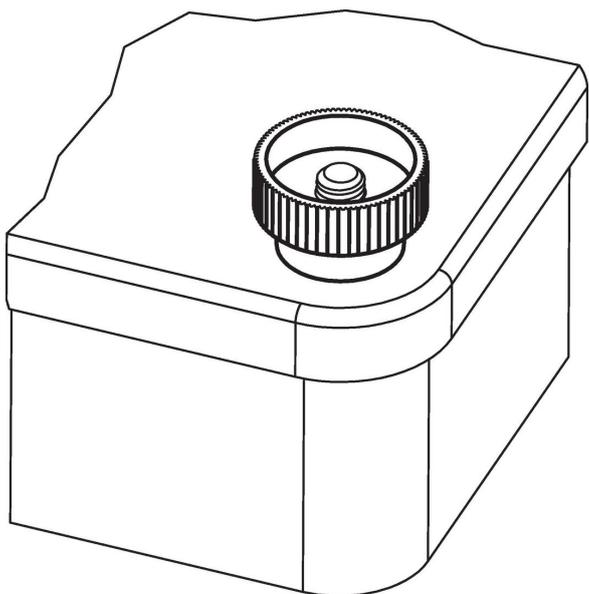

Cumplimiento

Para obtener información detallada sobre el cumplimiento, seleccione el número de artículo deseado.