


PACKED FULL OF POWER:  
**THE SUPERCRAFT PRINCIPLE**

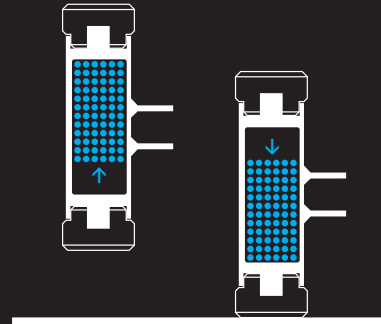

**Non-rebound work**

- 1 Joint-friendly
- 2 Reduced noise
- 3 Very high impact strength
- 4 Wear resistant inserts



**HALDER**

**STRIKE A BLOW  
WITH MANUFACTURING QUALITY**

**THE ORIGINAL  
MADE IN GERMANY.**

 


**ERWIN HALDER KG**

Erwin-Halder-Straße 5-9  
88480 Achstetten-Bronnen  
Germany

T +49 7392 7009-0  
F +49 7392 7009-160  
info@halder.com  
www.halder.com

Distributed by:



EN/12/2019


**HALDER**

**THE ORIGINAL  
FOR PROFESSIONALS**

Soft-face mallets and forestry tools



**SIMPLY SMART:  
THE SIMPLEX PRINCIPLE**

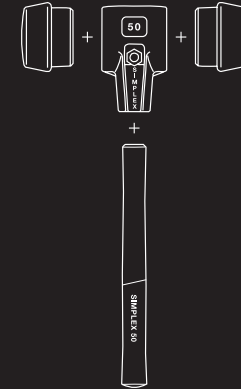

- 1 All wear parts can be easily replaced at any time
- 2 Interchangeable insert faces with different degrees of hardness
- 3 Housings of cast steel, aluminum or reinforced cast steel
- 4 High-quality wood or fibreglass handles

- **TPE-SOFT**  
soft / non-marring  
hardness ●○○○○
- **RUBBER COMPOSITION**  
medium hard / impact cushioning  
odorless / low-wear  
hardness ●●○○○
- **TPE-MID**  
medium hard / non-marring  
hardness ●●○○○
- **SUPERPLASTIC**  
medium hard / very durable  
wear-resistant  
hardness ●●●○○
- **PLASTIC**  
hard / oil and grease resistant  
hardness ●●●●○
- **NYLON**  
hard / very wear-resistant  
no chipping / oil and grease resistant  
hardness ●●●●○
- **SOFT METAL**  
hard / heat-proof  
hardness ●●●●●
- **COPPER**  
with plastic socket / hard  
hardness ●●●●●

# THE PERFECT HAMMER FOR EACH JOB



Both as a pro and as a handyman, you need two things to get excellent work results: the ambition to always do a top job, and the tools to support you in this.

For nearly 80 years, Halder soft-face mallets and forestry tools have stood for smart solutions and materials of the highest quality, made in Germany.



## CONSTRUCTION / GARDENING / LANDSCAPING

### → Floor tiling, paving (sensitive material)

3113 SIMPLEX soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm



 
### → Curbstone setting, paving, formwork construction

3027 SIMPLEX soft-face mallet · rubber comp./superplastic · Ø 30-80 mm



### → Curbstone setting, bracket stone setting

3027 SIMPLEX soft-face mallet · rubber comp./superplastic · Ø 80-100 mm



### → Natural stone setting masonry-/stairs setting

3013 SIMPLEX soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm



### → Concrete formwork

 
3366 SUPERCRAFT sledge hammer, non-rebound · Ø 80-100 mm



## MAINTENANCE / REPAIR

### → Mild to moderate work

3968 BASEPLEX soft-face mallet · cellulose acetate/nylon · Ø 25-50 mm



### → Powerful work

3026 SIMPLEX soft-face mallet · rubber comp./plastic · Ø 30-60 mm



### → Automotive and truck sector

3366 SUPERCRAFT soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm



3389 SUPERCRAFT soft-face mallet, non-rebound · 3-comp.-handle · Ø 40-60 mm



3666 MAXXCRAFT locksmith's hammer · 300-1000 g



### → Automotive and truck sector

3029 SIMPLEX soft-face mallet · rubber comp./soft metal · Ø 30-80 mm



3749 SIMPLEX soft-face mallet · copper/soft metal · Ø 30-40 mm



3389 SUPERCRAFT soft-face mallet, non-rebound · 3-comp.-handle · Ø 40-60 mm



3408 Punch · Ø 10-15 mm



### → Changing stucked tires

3379 BLACKCRAFT soft-face mallet, non-rebound · Ø 40-60 mm



## JOINERY / CARPENTRY

### → Setting light/sensitive workpieces, veneering, furniture assembly

3117 SIMPLEX soft-face mallet · TPE-soft/superplastic · 50:40 · Ø 50 mm



### → Window and door construction

3380 SECURAL soft-face mallet, non-rebound · 30x40 mm



### → Pin driving

3666 MAXXCRAFT locksmith's hammer · 300-1000 g



### → Roof setting

3366 SUPERCRAFT sledge hammer, non-rebound · Ø 80-100 mm



## INTERIOR WORK

### → Parquet and laminate flooring

3380 SECURAL soft-face mallet, non-rebound · 30x40 mm



3666 MAXXCRAFT locksmith's hammer · 300-1000 g



### → Floor tiling

3113 SIMPLEX soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm



### → Drywall construction

3013 SIMPLEX soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm



### → Install ceiling moldings

3408 Drop-mallet, non-rebound · Ø 20-50 mm



## SHEET METAL FORMING

### → Folding and bending work

 
3366 SUPERCRAFT soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm



3380 SECURAL soft-face mallet, non-rebound · 30x40 mm



3968 BASEPLEX soft-face mallet · cellulose acetate/nylon · Ø 25-50 mm



### → Installation work

3380 SECURAL soft-face mallet, non-rebound · 30x40 mm



3906 BASEPLEX soft-face mallet · cellulose acetate · Ø 25-50 mm



3677 FERROPLEX combi hammer · Ø 30-35 mm



## METALWORKING INDUSTRY

### → Positioning and adjusting of workpieces

3366 SUPERCRAFT soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm



3377 SUPERCRAFT soft-face mallet, non-rebound · Steel tube handle · Ø 25-70 mm



3380 SECURAL soft-face mallet, non-rebound · 30x40 mm



3028 SIMPLEX soft-face mallet · nylon/rubber comp. · Ø 30-80 mm



3408 Drop-mallet, non-rebound · Ø 20-50 mm



### → Straightening work, plant construction

3748 SIMPLEX soft-face mallet · copper/nylon · Ø 30-40 mm



3666 MAXXCRAFT locksmith's hammer · 300-1000 g



### → Housing assembly, mould construction

3089 SIMPLEX soft-face mallet · nylon/soft metal · Ø 30-80 mm



 
## AGRICULTURE / FORESTRY

### → Fence construction

3007 SIMPLEX sledge hammer · superplastic · Ø 80-140 mm



3366 SUPERCRAFT sledge hammer, non-rebound · Ø 80-100 mm



### → Splitting 1-metre logs, wedge work

3007 SIMPLEX splitting maul · 4.100 g



### → Splitting of coniferous wood, wedge work

3007 SIMPLEX splitting axe · 2.700 g



### → Splitting of hardwood, wedge work

3007 SIMPLEX splitting axe with wedge bars · 2.840 g



### → Splitting 1-metre logs

3556 Halder twisted splitting wedge



### → Splitting of smaller logs/kindling

3555 Halder hand axe · forged



Further models and combinations, see [www.halder.com](http://www.halder.com)