

Sormimutterit kauluksella • DIN 466

24780.0330



Tuotekuvaus

Knurled nuts are very versatile. Three material versions for the different requirements

- Steel, blackened
 - Steel, zinc-plated by galvanization
 - Stainless steel
- are available.

Knurled nuts can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

Sormimutterit kauluksella valmistetaan DIN 467 -standardin mukaisesti.

Materiaali

- Teräs, sinkitty galvanoimalla, laatuluokka 5

Lisätietoja


Huomioi

Pyällyksen syvyys ja tiheys voi poiketa DIN standardista.

Lisää tuotteita

- Litteät sormimutterit, DIN 467


Piirustus

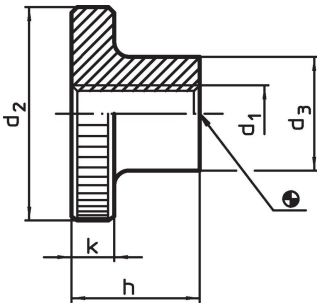

Tilaustiedot

| Ulkomitat | | | | | [g] | Til.nro |
|----------------|----------------|----------------|-----|-----|-----|------------|
| d ₁ | d ₂ | d ₃ | h | k | | |
| Teräs | | | | | | |
| M3 | 12 | 6 | 7,5 | 2,5 | 3 | 24780.0330 |

Sovellusesimerkki

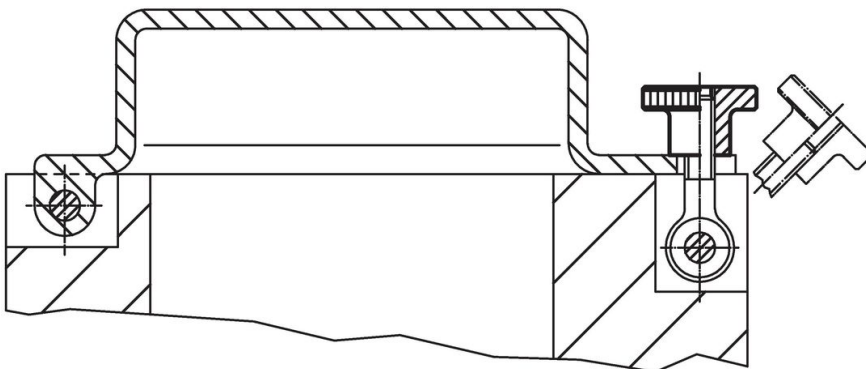

Vaatimuksenmukaisuus

RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset.

Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 27.06.2024.

Ei sisällä Prop 65 aineita

Ei sisällä Proposition 65 -aineita.
<https://www.P65Warnings.ca.gov/>

Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."