

Saranat • Sinkkipainevalu, palautusjousi, lukitusasennot

25164.0105



Tuotekuvaus

Hinges from zinc die-cast with indexing positions hold door and covers in fixed positions. It avoids undesired automatic closing or opening. This is an advantage for example when filling machines and facilities or during maintenance and repairs.

The version with the indexing positions -3° and 117° (picture 2) also ensures that the door or cover presses slightly against the housing frame by the -3° when closed.

These hinges from zinc die-cast are characterised by their simple and timeless design.

Materiaali

Holkki

- Sinkkivalu, muovipinnoite, musta RAL 9005, matta

Akseli

- Ruostumaton teräs 1.4305

Jousi


- Jousiteräslanka

Lisätietoja

Lisää tuotteita

- Välilevyt, saranoille
- Kierrelevyt, saranoille

Piirustus

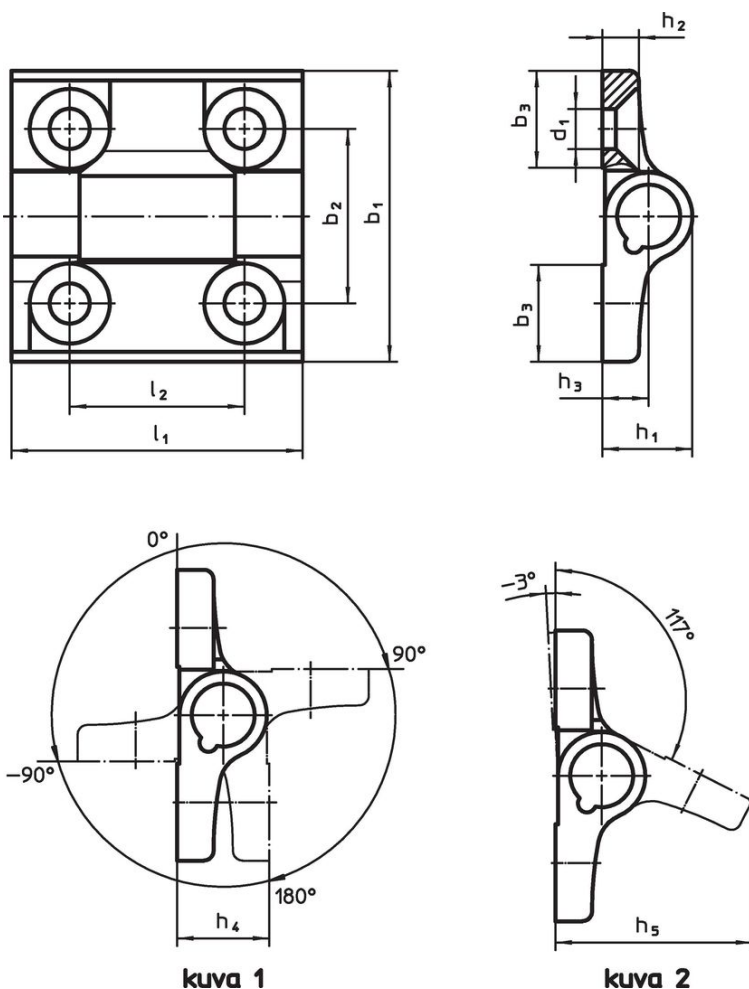

kuva 1

kuva 2

Tilaustiedot

Ulkomitat											max. [°C]	[g]	Til.nro		
b ₁	l ₁	b ₂	b ₃	d ₁	h ₁	h ₂	h ₃	h ₄	h ₅	l ₂					
lukitusasennot -90°, 0°, 90° ja 180° – Kuva 1, Sinkkipainevalu, musta															
60	60	36	20	8,3	18,5	7,5	9,5	19	40,5	36	80	152	25164.0105		

Vaatimuksenmukaisuus

RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset

Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 23.01.2024.

Ei sisällä Prop 65 aineita

Ei sisällä Prop 65 -aineita
<https://www.P65Warnings.ca.gov/>

Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."