

## Saranat • Pitkä rakenne

25165.0030



## Tuotekuvaus

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

## Materiaali


## Holkki

- Ruostumaton teräs 1.4301

## Akseli

- Ruostumaton teräs 1.4301


## Piirustus

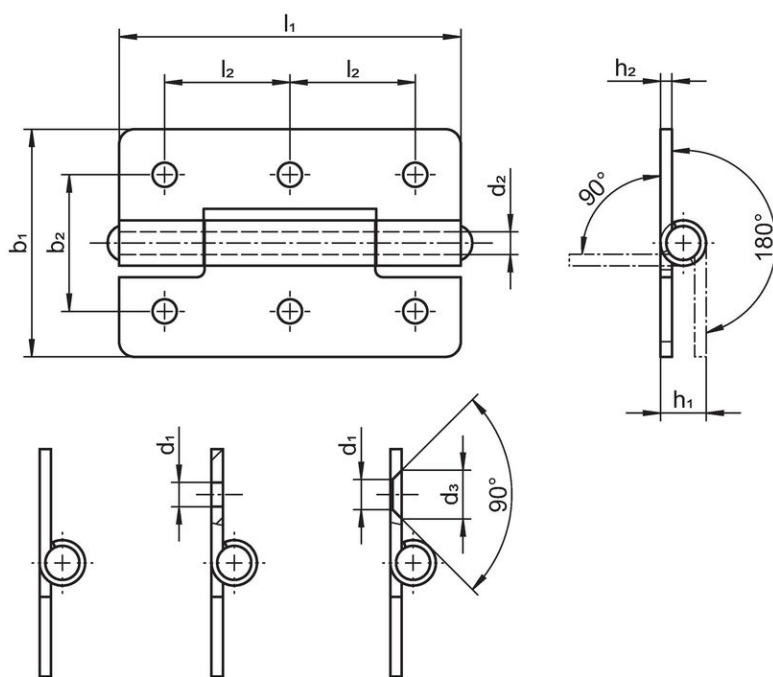


kuva 1

kuva 2

kuva 3

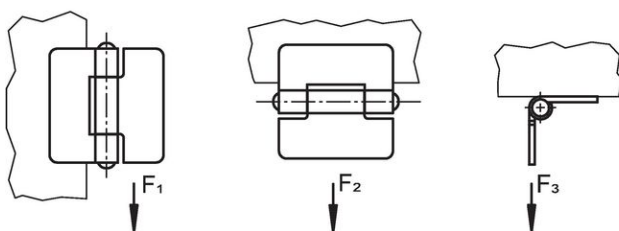

## Tilaustiedot

Ulkomitat					Pitovoima				Til.nro	
$b_1$	$l_1$	$d_2$	$h_1$ ~	$h_2$	$F_1$ ~	$F_2$ ~	$F_3$ ~			[g]
[mm]									[N]	
ilman reikiä – Kuva 1, Ruostumaton teräs										
40	60	4	8	2	2400	1500	1300	52	25165.0030	

## Vaatumuksenmukaisuus

## RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset.

## Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 27.06.2024.

## Ei sisällä Prop 65 aineita

Ei sisällä Proposition 65 -aineita.

<https://www.P65Warnings.ca.gov/>

## Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."