

## Saranat

25165.0060



### Tuotekuvaus

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

### Materiaali



#### Holkki

- Ruostumaton teräs 1.4301

#### Akseli

- Ruostumaton teräs 1.4301

### Piirustus

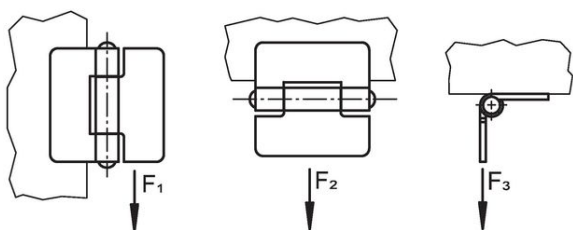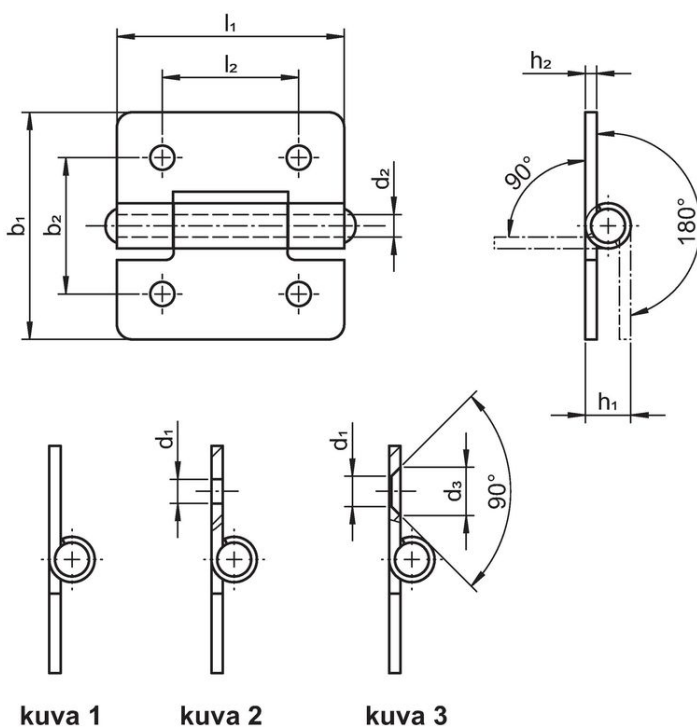

### Tilaustiedot

b <sub>1</sub>	l <sub>1</sub>	Ulkomitat			h <sub>2</sub>	F <sub>1</sub> ~	Pitovoima		[g]	Til.nro
		d <sub>2</sub>	h <sub>1</sub> ~	[mm]			F <sub>2</sub> ~ [N]	F <sub>3</sub> ~		
ilman reikiä – Kuva 1, Ruostumaton teräs										
60	60	6	10	2	2800	2500	1000	83	25165.0060	

## Vaatimuksenmukaisuus

### RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset.

### Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 27.06.2024.

### Ei sisällä Prop 65 aineita

Ei sisällä Proposition 65 -aineita.  
<https://www.P65Warnings.ca.gov/>

### Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."