

**Saranat** • elongated on one side  
25165.2080



**Tuotekuvaus**

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

**Materiaali**


**Holkki**

- Teräs, galvanoitu, passivoitu

**Akseli**

- Ruostumaton teräs 1.4301


**Piirustus**

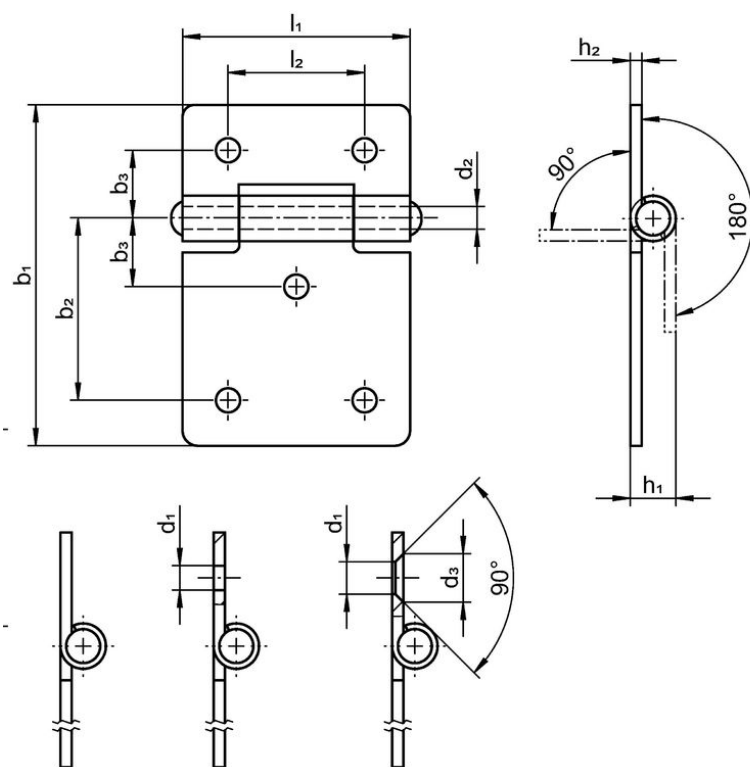

picture 1

picture 2

picture 3

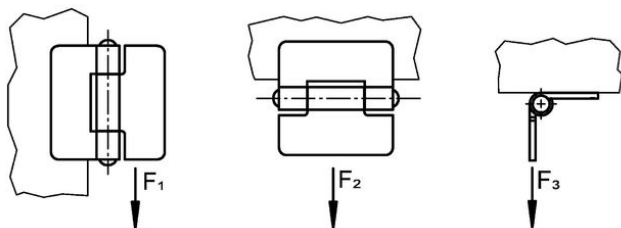

## Tilaustiedot

| Ulkomitat   |                |                |                |                |                |                |                     |                |                | Pitovoima           |                            |                     | [g] | Til.nro    |
|---|----------------|----------------|----------------|----------------|----------------|----------------|---------------------|----------------|----------------|---------------------|----------------------------|---------------------|-----|------------|
| b <sub>1</sub>                                    | l <sub>1</sub> | b <sub>2</sub> | b <sub>3</sub> | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | h <sub>1</sub><br>~ | h <sub>2</sub> | l <sub>2</sub> | F <sub>1</sub><br>~ | F <sub>2</sub><br>~<br>[N] | F <sub>3</sub><br>~ |     |            |
| [mm]  |                |                |                |                |                |                |                     |                |                |                     |                            |                     |     |            |
| with bores for countersunk screws – Kuva 3, Teräs |                |                |                |                |                |                |                     |                |                |                     |                            |                     |     |            |
| 90  | 60             | 48             | 18             | 5              | 6              | 8,3            | 10                  | 2              | 36             | 1100                | 2500                       | 1000                | 108 | 25165.2080 |

## Vaatimuksenmukaisuus

## RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset

## Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 23.01.2024.

## Ei sisällä Prop 65 aineita

Ei sisällä Prop 65 -aineita  
<https://www.P65Warnings.ca.gov/>

## Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."