


Ristinupit • DIN 6335 kevytmetallia EH 24630.

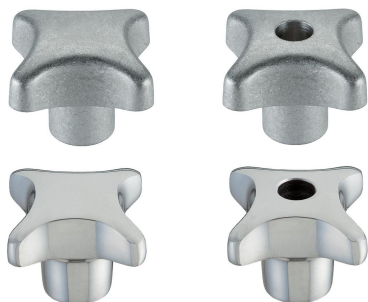

Tuotekuvaus


Nämä ristinupit valmistetaan DIN 6335 mukaisesti.

Materiaali


Kahva

- Kevytmetalli Al, kiillottamaton tai kiillotettu


Piirustus

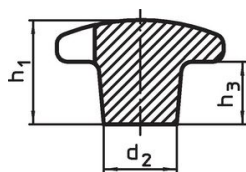



kuva 1

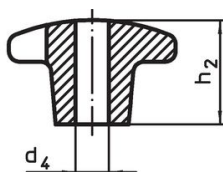


kuva 2

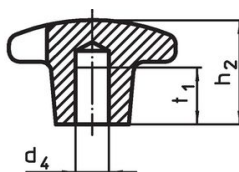

kuva 3

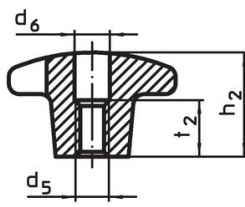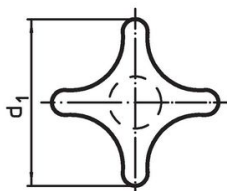


kuva 4

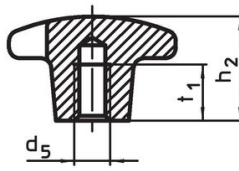


kuva 5

Tilaustiedot

| d ₁ | d ₂ | d ₄ H7 | d ₅ | Ulkomitat | | | | | | [g] | Til.nro | |
|--|----------------|----------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|---------|------------|
| | | | | d ₆ | h ₁ | h ₂ | h ₃ | t ₁ | t ₂ | | | |
| | | | | | | | | | | | [mm] | |
| Aihio, muoto A – Kuva 1, Kiillottamaton | | | | | | | | | | | | |
| 40 | 14 | – | – | – | 26 | – | 14 | – | – | – | 27 | 24630.0040 |
| 50 | 18 | – | – | – | 34 | – | 20 | – | – | – | 51 | 24630.0050 |
| 63 | 20 | – | – | – | 42 | – | 25 | – | – | – | 95 | 24630.0063 |
| 80 | 25 | – | – | – | 52 | – | 30 | – | – | – | 161 | 24630.0080 |
| Sileällä pohjareillä, muoto C – Kuva 3, Kiillottamaton | | | | | | | | | | | | |
| 40 | 14 | 8 | – | – | – | 25 | – | – | 15 | – | 23 | 24630.0240 |
| 50 | 18 | 10 | – | – | – | 32 | – | – | 18 | – | 42 | 24630.0250 |
| 63 | 20 | 12 | – | – | – | 40 | – | – | 22 | – | 73 | 24630.0263 |
| 80 | 25 | 16 | – | – | – | 50 | – | – | 28 | – | 138 | 24630.0280 |
| Sisäkierteellä, väljennetty, muoto D – Kuva 4, Kiillottamaton | | | | | | | | | | | | |
| 40 | 14 | – | M 8 | 8,4 | – | 25 | – | – | – | 13 | 23 | 24630.0340 |
| 50 | 18 | – | M10 | 10,5 | – | 32 | – | – | – | 16 | 44 | 24630.0350 |
| 63 | 20 | – | M12 | 13,0 | – | 40 | – | – | – | 20 | 70 | 24630.0363 |
| 80 | 25 | – | M16 | 17,0 | – | 50 | – | – | – | 20 | 129 | 24630.0380 |
| Sisäkierteellä, muoto E – Kuva 5, Kiillottamaton | | | | | | | | | | | | |
| 40 | 14 | – | M 8 | – | – | 25 | – | – | 15 | – | 24 | 24630.0440 |
| 50 | 18 | – | M10 | – | – | 32 | – | – | 18 | – | 46 | 24630.0450 |
| 63 | 20 | – | M12 | – | – | 40 | – | – | 22 | – | 74 | 24630.0463 |
| 80 | 25 | – | M16 | – | – | 50 | – | – | 28 | – | 142 | 24630.0480 |

| d ₁ | d ₂ | d ₄ H7 | d ₅ | Ulkomitat [mm] | | | | | |  | Til.nro |
|---|----------------|----------------------|----------------|-------------------|----------------|----------------|----------------|----------------|----------------|---|----------------------------|
| | | | | d ₆ | h ₁ | h ₂ | h ₃ | t ₁ | t ₂ | [g] | |
| Sileällä pohjareillä, muoto C – Kuva 3, Kiillotettu | | | | | | | | | | | |
| 40 | 14 | 8 | – | – | – | 25 | – | 15 | – | 23 | 24630.0640 |
| 50 | 18 | 10 | – | – | – | 32 | – | 18 | – | 42 | 24630.0650 |
| 63 | 20 | 12 | – | – | – | 40 | – | 22 | – | 73 | 24630.0663 |
| 80 | 25 | 16 | – | – | – | 50 | – | 28 | – | 138 | 24630.0680 |
| Sisäkierteellä, väljennetty, muoto D – Kuva 4, Kiillotettu | | | | | | | | | | | |
| 40 | 14 | – | M 8 | 8,4 | – | 25 | – | – | 13 | 23 | 24630.0740 |
| 50 | 18 | – | M10 | 10,5 | – | 32 | – | – | 16 | 44 | 24630.0750 |
| 63 | 20 | – | M12 | 13,0 | – | 40 | – | – | 20 | 70 | 24630.0763 |
| 80 | 25 | – | M16 | 17,0 | – | 50 | – | – | 20 | 129 | 24630.0780 |
| Sisäkierteellä, muoto E – Kuva 5, Kiillotettu | | | | | | | | | | | |
| 40 | 14 | – | M 8 | – | – | 25 | – | 15 | – | 24 | 24630.0840 |
| 50 | 18 | – | M10 | – | – | 32 | – | 18 | – | 46 | 24630.0850 |
| 63 | 20 | – | M12 | – | – | 40 | – | 22 | – | 74 | 24630.0863 |
| 80 | 25 | – | M16 | – | – | 50 | – | 28 | – | 142 | 24630.0880 |

Sovellusesimerkki

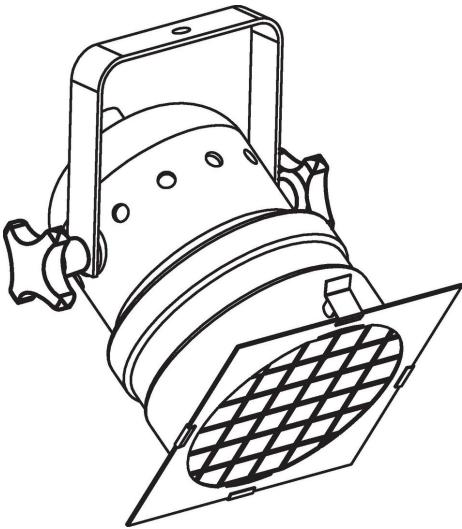

Vaatimuksenmukaisuus

Tarkat sopivuustiedot nähdäksesi valitse haluttu tuotenumero.