


Ristinupit • DIN 6335 kevytmetallia EH 24630.

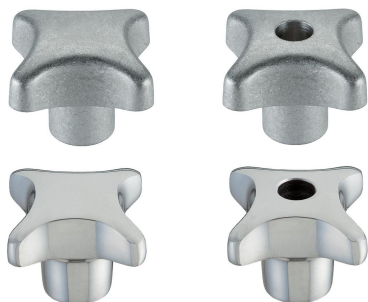

Tuotekuvaus


These palm grips are manufactured according to DIN 6335.

Materiaali


Kahva

- Kevytmetalli Al, kiillottamaton tai kiillotettu


Piirustus

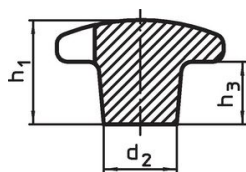



kuva 1

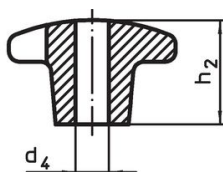


kuva 2

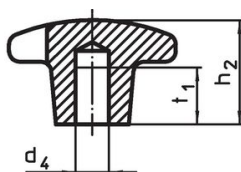

kuva 3

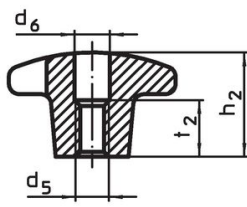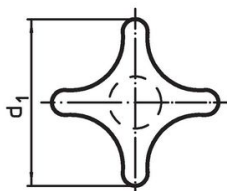

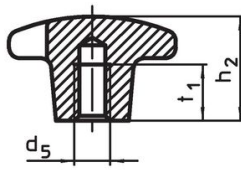

kuva 4




kuva 5

Tilaustiedot

d ₁	d ₂	d ₄ H7	d ₅	Ulkomitat [mm]							Til.nro	
											[g]	
Aihio, muoto A – Kuva 1, Kiillottamaton												
40	14	–	–	–	26	–	14	–	–	–	27	24630.0040
50	18	–	–	–	34	–	20	–	–	–	51	24630.0050
63	20	–	–	–	42	–	25	–	–	–	95	24630.0063
80	25	–	–	–	52	–	30	–	–	–	161	24630.0080
Sileällä pohjareillä, muoto C – Kuva 3, Kiillottamaton												
40	14	8	–	–	–	25	–	15	–	–	23	24630.0240
50	18	10	–	–	–	32	–	18	–	–	42	24630.0250
63	20	12	–	–	–	40	–	22	–	–	73	24630.0263
80	25	16	–	–	–	50	–	28	–	–	138	24630.0280
Sisäkierteellä, väljennetty, muoto D – Kuva 4, Kiillottamaton												
40	14	–	M 8	8,4	–	25	–	–	–	13	23	24630.0340
50	18	–	M10	10,5	–	32	–	–	–	16	44	24630.0350
63	20	–	M12	13,0	–	40	–	–	–	20	70	24630.0363
80	25	–	M16	17,0	–	50	–	–	–	20	129	24630.0380
Sisäkierteellä, muoto E – Kuva 5, Kiillottamaton												
40	14	–	M 8	–	–	25	–	15	–	–	24	24630.0440
50	18	–	M10	–	–	32	–	18	–	–	46	24630.0450
63	20	–	M12	–	–	40	–	22	–	–	74	24630.0463
80	25	–	M16	–	–	50	–	28	–	–	142	24630.0480

d ₁	d ₂	d ₄ H7	d ₅	Ulkomitat [mm]							Til.nro
				d ₆	h ₁	h ₂	h ₃	t ₁	t ₂	[g]	
Sileällä pohjareiällä, muoto C – Kuva 3, Kiillotettu											
40	14	8	–	–	–	25	–	15	–	23	24630.0640
50	18	10	–	–	–	32	–	18	–	42	24630.0650
63	20	12	–	–	–	40	–	22	–	73	24630.0663
80	25	16	–	–	–	50	–	28	–	138	24630.0680
Sisäkierteellä, väljennetty, muoto D – Kuva 4, Kiillotettu											
40	14	–	M 8	8,4	–	25	–	–	13	23	24630.0740
50	18	–	M10	10,5	–	32	–	–	16	44	24630.0750
63	20	–	M12	13,0	–	40	–	–	20	70	24630.0763
80	25	–	M16	17,0	–	50	–	–	20	129	24630.0780
Sisäkierteellä, muoto E – Kuva 5, Kiillotettu											
40	14	–	M 8	–	–	25	–	15	–	24	24630.0840
50	18	–	M10	–	–	32	–	18	–	46	24630.0850
63	20	–	M12	–	–	40	–	22	–	74	24630.0863
80	25	–	M16	–	–	50	–	28	–	142	24630.0880

Sovellusesimerkki

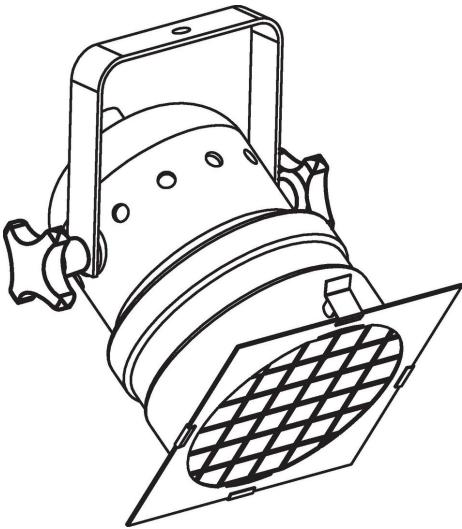

Vaatimuksenmukaisuus

Tarkat sopivuustiedot nähdäksesi valitse haluttu tuotenumero.