

## Saranat • elongated on one side

### EH 25165.



#### Tuotekuvaus

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

#### Materiaali


##### Holkki

- Ruostumaton teräs 1.4301
- Teräs, galvanoitu, passivoitu

##### Akseli

- Ruostumaton teräs 1.4301


#### Piirustus

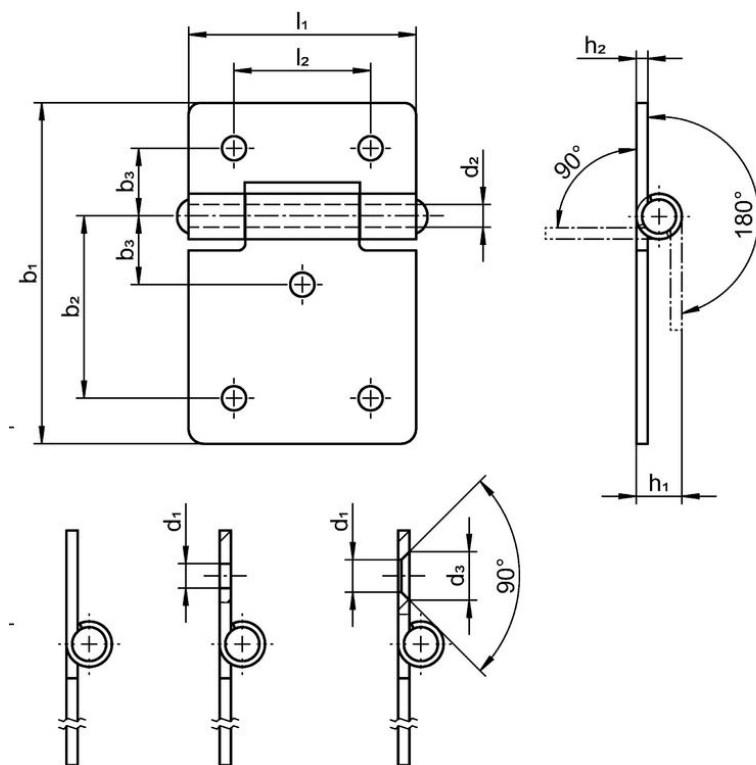

picture 1

picture 2

picture 3

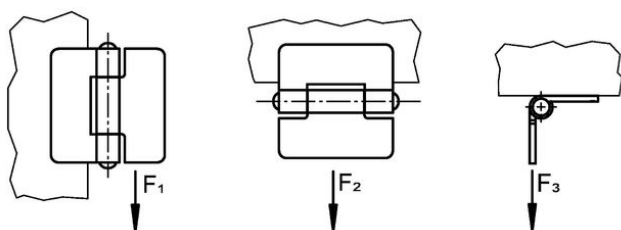

## Tilaustiedot

b <sub>1</sub>	l <sub>1</sub>	b <sub>2</sub>	b <sub>3</sub>	Ulkomitat						Pitovoima			[g]	Til.nro
				d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	l <sub>2</sub>	F <sub>1</sub>	F <sub>2</sub>	F <sub>3</sub>		
				[mm]						[N]				
<b>without bores – Kuva 1, Ruostumaton teräs</b>														
45	30	–	–	–	3	–	6	1,5	–	700	500	450	20	25165.0035
60	40	–	–	–	4	–	8	2,0	–	1200	1000	1000	47	25165.0055
75	50	–	–	–	6	–	10	2,0	–	1600	2000	1000	81	25165.0070
90	60	–	–	–	6	–	10	2,0	–	1100	2500	1000	111	25165.0080
<b>with bores – Kuva 2, Ruostumaton teräs</b>														
45	30	24,0	9,0	3,2	3	–	6	1,5	18	700	500	450	19	25165.0135
60	40	32,5	12,5	4,2	4	–	8	2,0	18	1200	1000	1000	45	25165.0155
75	50	40,0	15,0	5,2	6	–	10	2,0	30	1600	2000	1000	79	25165.0170
90	60	48,0	18,0	5,2	6	–	10	2,0	36	1100	2500	1000	108	25165.0180
<b>with bores – Kuva 2, Teräs</b>														
45	30	24,0	9,0	3,2	3	–	6	1,5	18	700	500	450	19	25165.1035
60	40	32,5	12,5	4,2	4	–	8	2,0	25	1200	1000	1000	45	25165.1055
75	50	40,0	15,0	5,2	6	–	10	2,0	30	1600	2000	1000	79	25165.1070
90	60	48,0	18,0	5,2	6	–	10	2,0	36	1100	2500	1000	108	25165.1080
<b>with bores for countersunk screws – Kuva 3, Ruostumaton teräs</b>														
45	30	24,0	9,0	4,0	3	6,4	6	1,5	18	700	500	450	19	25165.0235
60	40	32,5	12,5	5,0	4	8,3	8	2,0	25	1200	1000	1000	45	25165.0255
75	50	40,0	15,0	5,0	6	8,3	10	2,0	30	1600	2000	1000	79	25165.0270
90	60	48,0	18,0	5,0	6	8,3	10	2,0	36	1100	2500	1000	108	25165.0280
<b>with bores for countersunk screws – Kuva 3, Teräs</b>														
45	30	24,0	9,0	4,0	3	6,4	6	1,5	18	700	500	450	19	25165.2035
60	40	32,5	12,5	5,0	4	8,3	8	2,0	25	1200	1000	1000	45	25165.2055
75	50	40,0	15,0	5,0	6	8,3	10	2,0	30	1600	2000	1000	79	25165.2070
90	60	48,0	18,0	5,0	6	8,3	10	2,0	36	1100	2500	1000	108	25165.2080

## Vaatumuksenmukaisuus

## RoHS-yhteensopiva

Täyttävät direktiivin 2011/65/EU ja direktiivin 2015/863 vaatimukset

## Ei sisällä SVHC-aineita

Ei sisällä yli 0,1 % w/w SVHC-aineita - SVHC-luettelo 23.01.2024.

## Ei sisällä Prop 65 aineita

Ei sisällä Prop 65 -aineita

<https://www.P65Warnings.ca.gov/>

## Ei sisällä konfliktimineraaleja

Tämä tuote ei sisällä "konfliktimineraaleiksi" luokiteltuja aineita, kuten tantaalia, tinaa, kultaa tai volframia Kongon demokraattisesta tasavallasta tai sen naapurimaista."