


## Fixed Drilling Supports · fix

EH 1162.000 - EH 1162.300

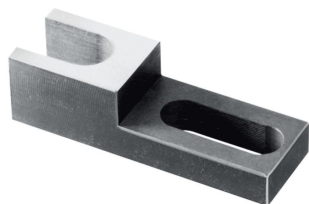


### Product Description

#### Material

- Steel, case-hardened, ground

### Drawing

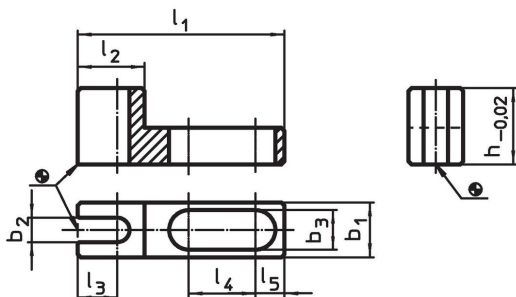

### Order information

System	Dimensions										Art. No.
	$l_1$	$l_2$	$l_3$	$l_4$	$l_5$	$b_1$	$b_2$	$b_3$	$h$	[g]	
V70/L12	68	22	13	22	9.5	18	8	13	25	92	<a href="#">1162.000</a>
V70/L12	88	38	20	26	9.5	28	16	13	25	214	<a href="#">1162.100</a>
V70/L12	98	40	20	31	9.5	38	24	13	25	321	<a href="#">1162.200</a>
V70/L12	108	45	20	37	11.5	48	35	17	25	399	<a href="#">1162.300</a>

### Compliance

#### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

#### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 23.01.2024.

#### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

#### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.