


## Spacers

EH 1007.400 - EH 1108.300

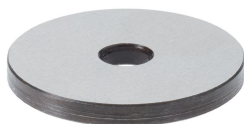


### Product Description

This mounting element is a system part of the T-slot system.

### Material

- Steel, case-hardened, ground

### Drawing

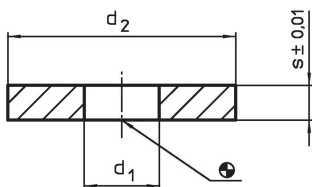

### Order information

System	Dimensions			[g]	Art. No.
	d <sub>1</sub>	d <sub>2</sub> [mm]	s		
V40	8.5	24.0	3	9	1007.400
V40	8.5	39.5	3	30	1007.500
V40	8.5	24.0	4	12	1007.600
V40	8.5	39.5	4	37	1007.700
V40	8.5	24.0	5	15	1007.800
V40	8.5	39.5	5	46	1007.900
V70/L12	13.0	39.5	3	27	1107.400
V70/L12	13.0	59.5	3	65	1107.500
V70/L12	13.0	39.5	4	36	1107.600
V70/L12	13.0	59.5	4	86	1107.700
V70/L12	13.0	39.5	5	44	1107.800
V70/L12	13.0	59.5	5	107	1107.900
V70/L12	13.0	39.5	10	85	1108.000
V70/L12	13.0	59.5	10	208	1108.100
V70/L12	13.0	39.5	20	170	1108.200
V70/L12	13.0	59.5	20	417	1108.300

### Compliance

#### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

#### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 27.06.2024.

#### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

#### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.