

ホルダー・スプリングプランジャー用 EH 22045.



製品説明

Holders are used to mount spring plungers on the side. Ball-ended thrust screws, thrust screws, grub screws or similar can also be screwed into the thread. The mounting thread is positioned 90° to the mounting direction in the holder. The slotted holes allow precise positioning of the holder during installation.


材質

- ステンレス鋼1.4308, 精密鑄造、プラスト処理

組立

Slotted holes are provided for mounting the holder. This allows it to be positioned precisely in the longitudinal direction. The mounting thread, e.g. for a spring plungers, is continuous. This means that a lock nut can be used to secure it after adjustment.

寸法図

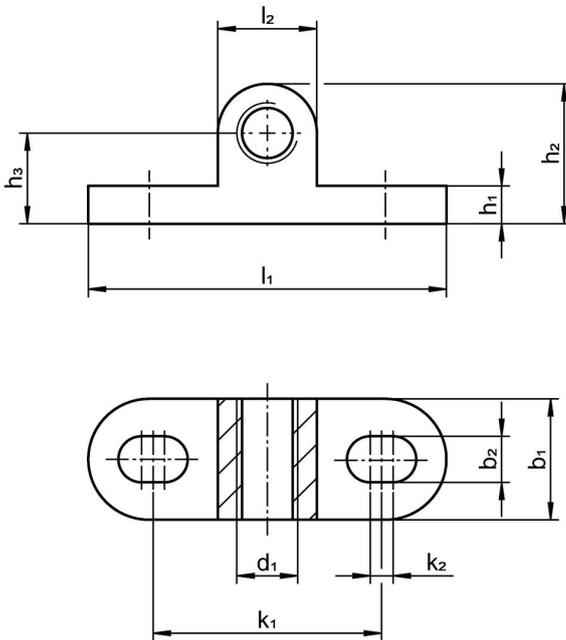

発注情報

| 寸法 | | | | | | | | | | | 適合ねじ | 📏 | 製品番号 |
|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|--|------|-----|------------|
| d ₁ | b ₁ | b ₂ | h ₁ | h ₂ | h ₃ | k ₁ | k ₂ | l ₁ | l ₂ | | [mm] | [g] | |
| [mm] | | | | | | | | | | | | | |
| 両面型 | | | | | | | | | | | | | |
| M 4 | 8 | 3 | 2,5 | 9,5 | 6 | 16 | 1,5 | 25 | 7 | | M3 | 5 | 22045.0004 |
| M 5 | 10 | 4 | 3,5 | 12,0 | 8 | 20 | 2,0 | 32 | 8 | | M4 | 9 | 22045.0005 |
| M 6 | 12 | 5 | 4,0 | 15,0 | 10 | 24 | 2,5 | 38 | 10 | | M5 | 15 | 22045.0006 |
| M 8 | 16 | 6 | 5,0 | 18,5 | 12 | 30 | 3,0 | 47 | 13 | | M6 | 35 | 22045.0008 |
| M10 | 20 | 8 | 6,0 | 23,0 | 15 | 38 | 4,0 | 60 | 16 | | M8 | 58 | 22045.0010 |

法令(コンプライアンス)

RoHS準拠

2011/65/EUと2015/863指令に適合しています

SVHC材の含有は無し

0.1%(質量%濃度)以上の高懸念物質(SVHC)は使用していません-2024年6月27日SVHCリスト対象.

プロポジション65の物質は含有していません

プロポジション65の指定物質は含まれていません

<https://www.P65Warnings.ca.gov/>

紛争物質は使用していません

本製品は、コンゴ民主共和国や隣国地域から産出されるチタン、錫、金、タングステンなどのいかなる「紛争鉱物」に由来する物質を使っていません。