

パームグリップ、オネジ付・DIN6335プラスチック

EH 24730.



製品説明

材質

グリップ

- 熱硬化性樹脂 (PF31)、黒 (RAL 9005相当)

ねじ


- スチール、亜鉛めっき
- ステンレス鋼 A2 (SUS304に類似)

更なる情報

備考

長さ違いや黄銅・ステンレスネジなどの特殊仕様についてはお問い合わせください。

寸法図

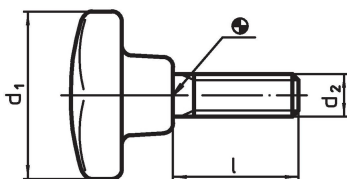

発注情報

d ₁	寸法		max. [°C]	[g]	製品番号
	d ₂ [mm]	l			
形状L, 鋼					
25	M 5	10	110	6,6	24730.0051
25	M 5	15	110	7,0	24730.0053
25	M 5	20	110	7,5	24730.0056
25	M 5	25	110	8,1	24730.0058
25	M 5	30	110	8,9	24730.0059
32	M 6	15	110	11,0	24730.0101
32	M 6	20	110	13,0	24730.0104
32	M 6	25	110	13,0	24730.0106
32	M 6	30	110	14,0	24730.0107
32	M 6	40	110	16,0	24730.0110
40	M 8	20	110	24,0	24730.0152
40	M 8	25	110	25,0	24730.0154
40	M 8	30	110	26,0	24730.0155
40	M 8	40	110	30,0	24730.0158
40	M 8	50	110	32,0	24730.0160
50	M10	25	110	41,0	24730.0202
50	M10	30	110	48,0	24730.0203
50	M10	40	110	51,0	24730.0206
50	M10	50	110	56,0	24730.0208
50	M10	60	110	68,0	24730.0209
63	M12	30	110	99,0	24730.0251
63	M12	40	110	93,0	24730.0254
63	M12	50	110	99,0	24730.0256
63	M12	60	110	105,0	24730.0257
63	M12	80	110	112,0	24730.0260
80	M16	40	110	198,0	24730.0302
80	M16	50	110	214,0	24730.0304
80	M16	60	110	219,0	24730.0305
80	M16	80	110	251,0	24730.0308

d ₁	寸法		max. [°C]	[g]	製品番号
	d ₂ [mm]	l			
形状L, ステンレス鋼					
25	M 5	10	110	6,6	24730.1051
25	M 5	15	110	7,0	24730.1053
25	M 5	20	110	7,5	24730.1056
25	M 5	25	110	8,1	24730.1058
25	M 5	30	110	8,9	24730.1059
32	M 6	15	110	11,0	24730.1101
32	M 6	20	110	13,0	24730.1104
32	M 6	25	110	13,0	24730.1106
32	M 6	30	110	14,0	24730.1107
32	M 6	40	110	16,0	24730.1110
40	M 8	20	110	24,0	24730.1152
40	M 8	25	110	25,0	24730.1154
40	M 8	30	110	26,0	24730.1155
40	M 8	40	110	30,0	24730.1158
40	M 8	50	110	32,0	24730.1160
50	M10	25	110	41,0	24730.1202
50	M10	30	110	48,0	24730.1203
50	M10	40	110	51,0	24730.1206
50	M10	50	110	56,0	24730.1208
50	M10	60	110	68,0	24730.1209
63	M12	30	110	99,0	24730.1251
63	M12	40	110	93,0	24730.1254
63	M12	50	110	99,0	24730.1256
63	M12	60	110	105,0	24730.1257
63	M12	80	110	112,0	24730.1260
80	M16	40	110	198,0	24730.1302
80	M16	50	110	214,0	24730.1304
80	M16	60	110	219,0	24730.1305
80	M16	80	110	251,0	24730.1308

法令(コンプライアンス)

RoHS準拠

2011/65/EUと2015/863指令に適合しています

SVHC材の含有は無し

0.1%(質量%濃度)以上の高懸念物質(SVHC)は使用していません-2024年6月27日SVHCリスト対象.

プロポジション65の物質は含有していません

プロポジション65の指定物質は含まれていません

<https://www.P65Warnings.ca.gov/>

紛争物質は使用していません

本製品は、コンゴ民主共和国や隣国地域から産出されるチタン、錫、金、タングステンなどのいかなる「紛争鉱物」に由来する物質を使っていません。