


Excenter-spanklemmen • with slot tenon

23270.0410

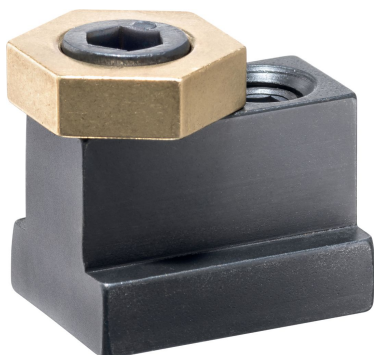

Productbeschrijving

The eccentric clamping clamps can be used for quick and easy workpiece clamping directly on the machine table or a base plate with T-slots.

These eccentric clamping clamps with slot tenon are locked in a T-slot, for example on the machine table, with a thrust screw. Clamping takes place via the clamping screw with eccentric head. The brass basic element ensures gentle and secure clamping.

The eccentric clamping clamps with slot tenon have the following characteristics:

- Brass base element for material-friendly clamping
- Quick clamping thanks to clamping screw with eccentric head
- High clamping force is achieved
- Low design enables the machining of flat workpieces
- The compact dimensions enable space-saving multiple clamping

Materiaal

Excenterschroef

- Staal

Stelschroef

- staal, gezwart


Huls

- messing

Slot tenon

- staal, gehard, gezwart


Tekening

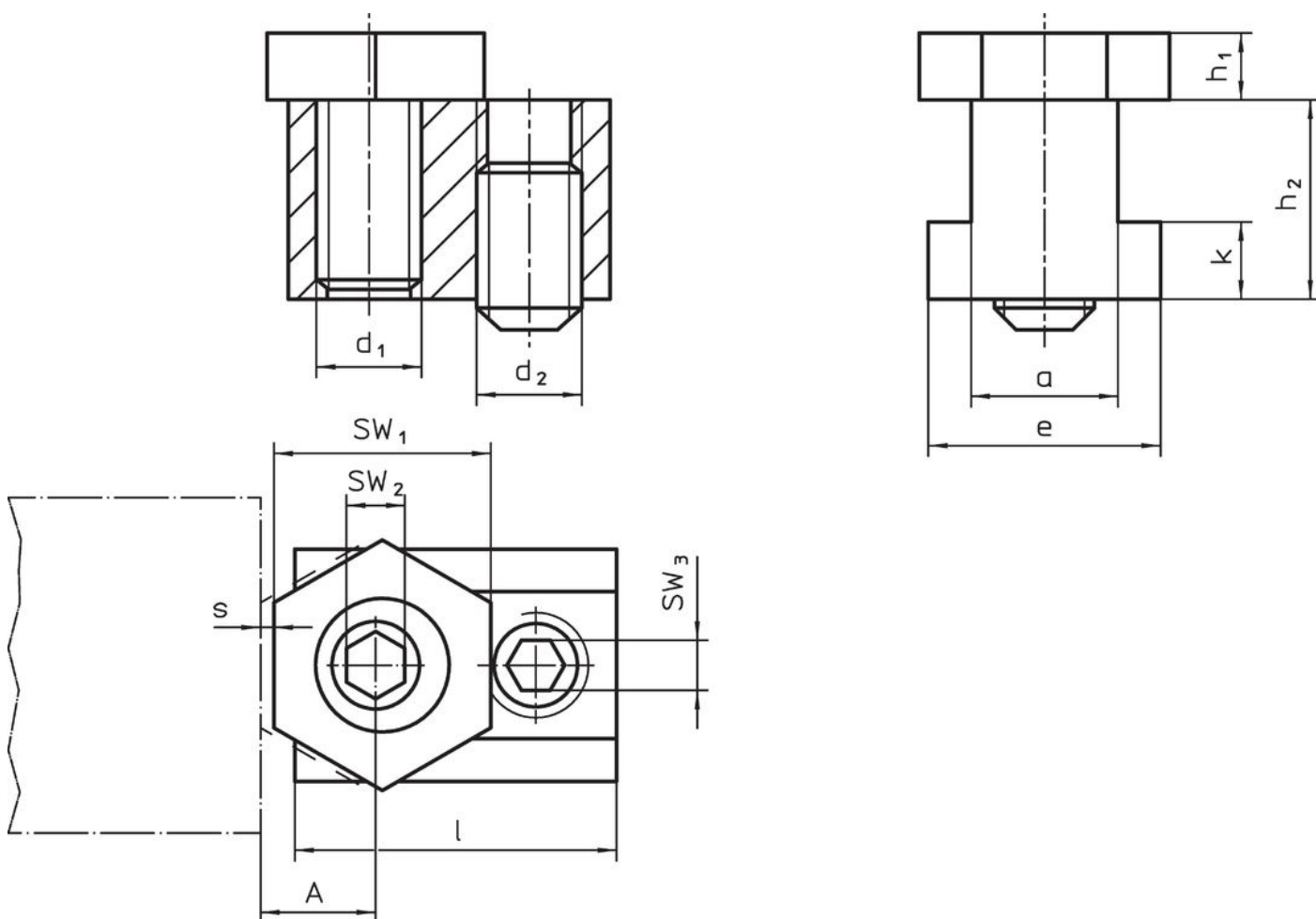

Bestelinformatie

Nominale gleufmaat	d ₁	a	e	Afmetingen					A	SW			Spankracht max.	Aandraai- moment SW ₂ max.	Aandraai- moment SW ₃ max.	Artikelnr.	
				h ₁	h ₂	k	s	l		SW ₁	SW ₂	SW ₃					
[mm]				[mm]					[mm]	[mm]			[kN]	[Nm]	[Nm]	[g]	
10	M6	9,8	14,3	4,8	14,3	4,4	1	23,2	7,8	16	4	3	3,4	10	8	35	23270.0410

Toepassingsvoorbeeld

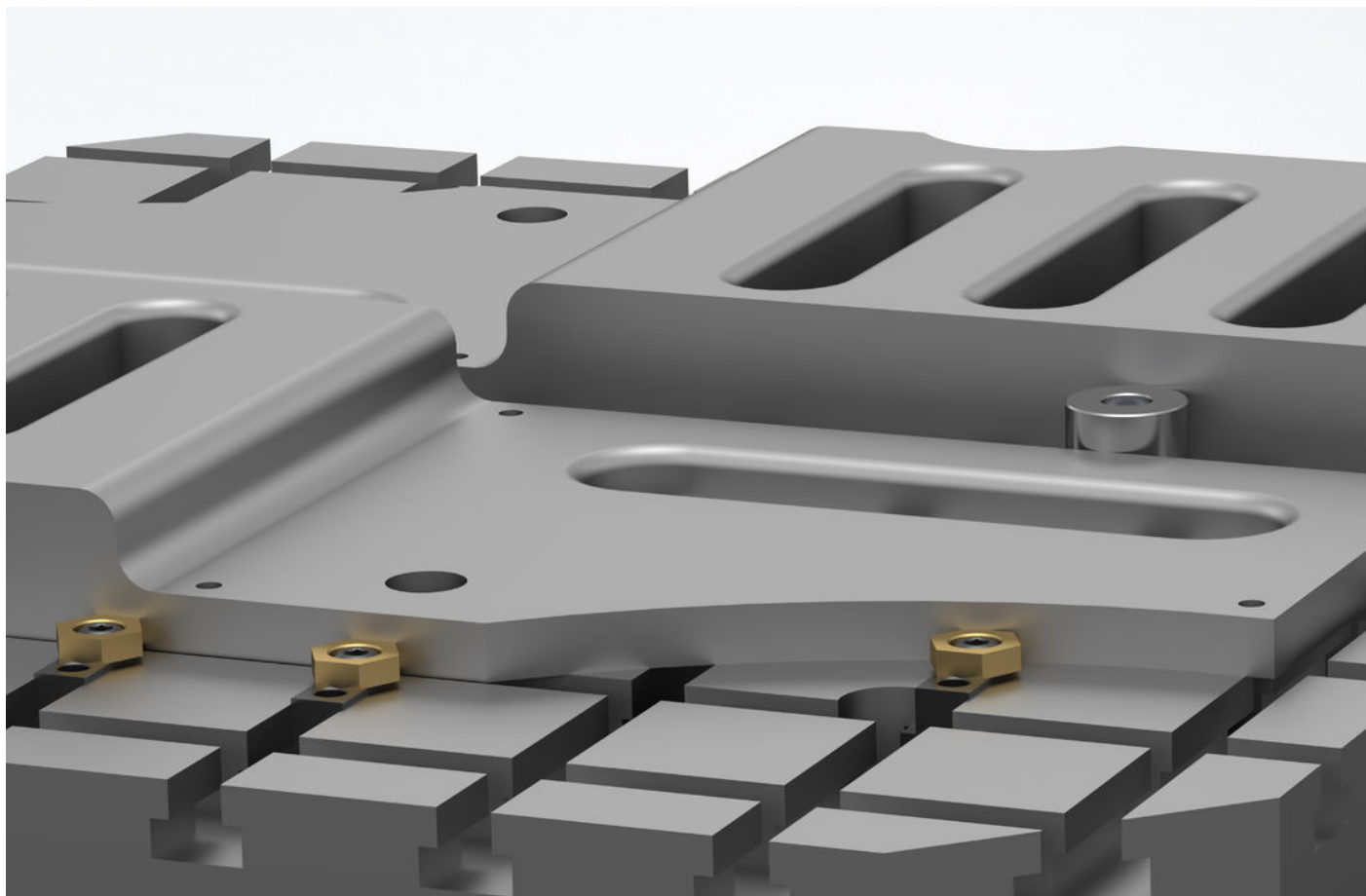

Voldoet

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 27.06.2024.

Geen propositie 65 stoffen inbegrepen
<https://www.P65Warnings.ca.gov/>