

Scharnieren

25165.0015



Productbeschrijving

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Materiaal


Huls

- RVS 1.4301


As

- RVS 1.4301

Tekening

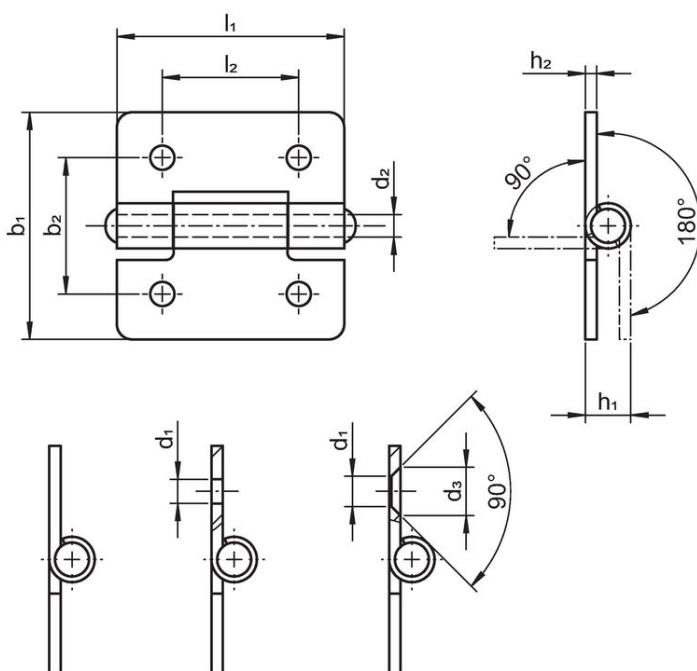

picture 1 picture 2 picture 3

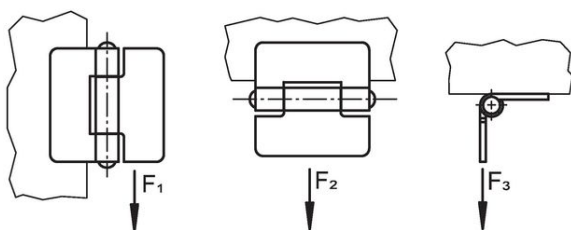

Bestelinformatie

b ₁	l ₁	Afmetingen			h ₂	Klemkracht			[g]	Artikelnr.		
		d ₂	h ₁	~		F ₁	F ₂	F ₃				
without bores – Afbeelding 1, Roestvast staal												
30	30	3	6	~	1,5	700	~	500	~	500	15	25165.0015

Voldoet

Conform RoHS

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC stoffen

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 23.01.2024.

Bevat geen propositie 65 stoffen

Geen propositie 65 stoffen inbegrepen
<https://www.P65Warnings.ca.gov/>

Vrij van conflictmineralen

Dit product bevat geen stoffen die worden aangeduid als "conflictmineralen" zoals tantaal, tin, goud of wolfram uit de Democratische Republiek Congo of aangrenzende landen."