

Scharnieren

25165.0060



Productbeschrijving

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Materiaal


Huls

- RVS 1.4301


As

- RVS 1.4301

Tekening

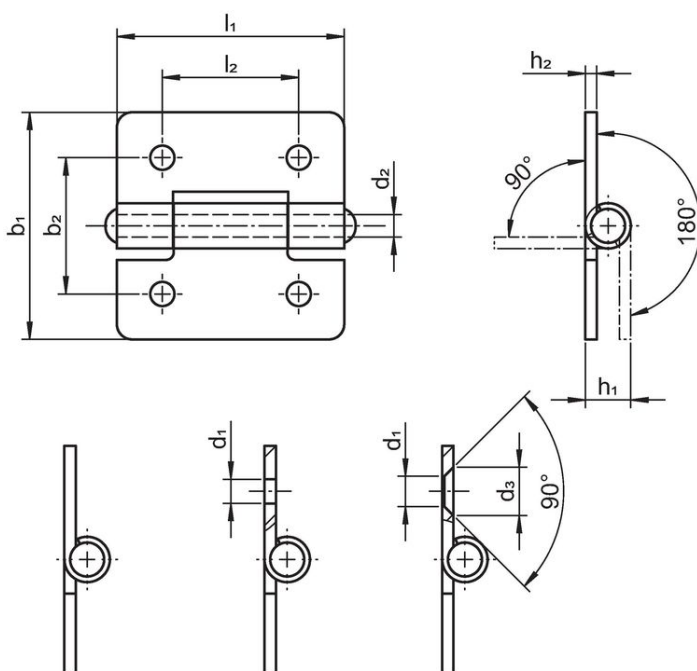

Afbeelding 1 Afbeelding 2 Afbeelding 3

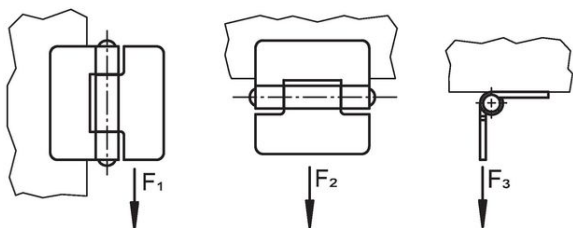

Bestelinformatie

Afmetingen					Klemkracht			Artikelnr.
b_1	l_1	d_2	h_1	h_2	F_1	F_2	F_3	
[mm]					~	~	~	[g]
without bores – Afbeelding 1, Roestvast staal								
60	60	6	10	2	2800	2500	1000	83
								25165.0060

Voldoet

Conform RoHS

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC stoffen

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 27.06.2024.

Bevat geen propositie 65 stoffen

Geen propositie 65 stoffen inbegrepen
<https://www.P65Warnings.ca.gov/>

Vrij van conflictmineralen

Dit product bevat geen stoffen die worden aangeduid als "conflictmineralen" zoals tantaal, tin, goud of wolfram uit de Democratische Republiek Congo of aangrenzende landen."