

Scharnieren • elongated on one side

25165.0270



Productbeschrijving

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Materiaal


Huls

- RVS 1.4301


As

- RVS 1.4301


Tekening

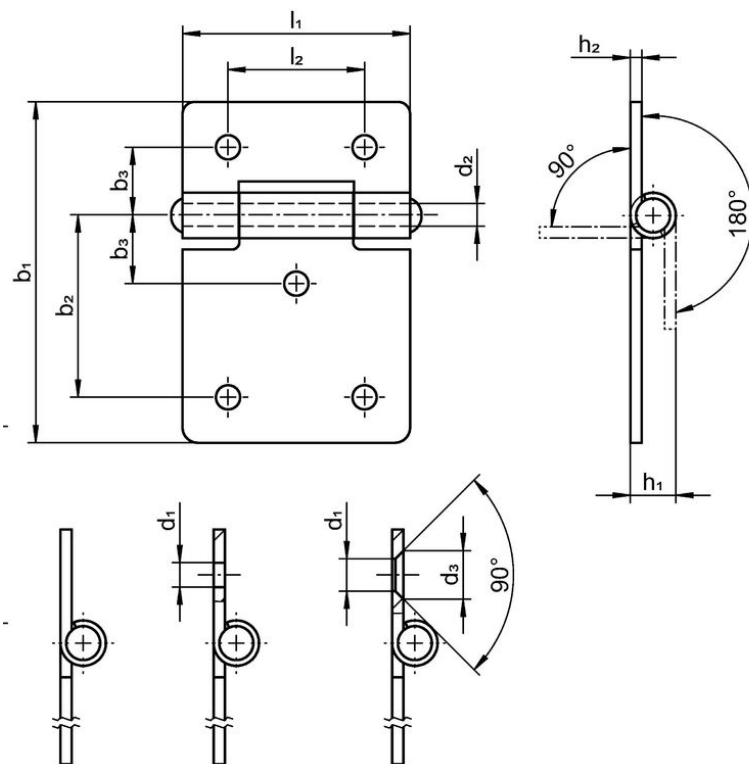

picture 1 picture 2 picture 3

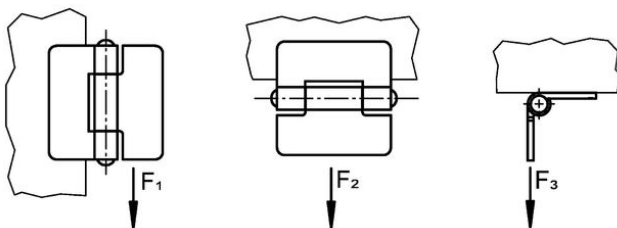

Bestelinformatie

b ₁	l ₁	b ₂	b ₃	Afmetingen						Klemkracht				Artikelnr.	
				d ₁	d ₂	d ₃	h ₁ ~	h ₂	l ₂	F ₁ ~	F ₂ ~ [N]	F ₃ ~			
[mm]														[g]	
with bores for countersunk screws – Afbeelding 3, Roestvast staal															
75	50	40	15	5	6	8,3	10	2	30	1600	2000	1000	79	25165.0270	

Voldoet

Conform RoHS

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC stoffen

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 23.01.2024.

Bevat geen propositie 65 stoffen

Geen propositie 65 stoffen inbegrepen

<https://www.P65Warnings.ca.gov/>

Vrij van conflictmineralen

Dit product bevat geen stoffen die worden aangeduid als "conflictmineralen" zoals tantaal, tin, goud of wolfram uit de Democratische Republiek Congo of aangrenzende landen."