

Scharnieren
25165.2015



Productbeschrijving

The different versions cover many applications that require a low load. These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Materiaal


Huls

- staal, verzinkt door galvanisatie, gepassiveerd


As

- RVS 1.4301

Tekening

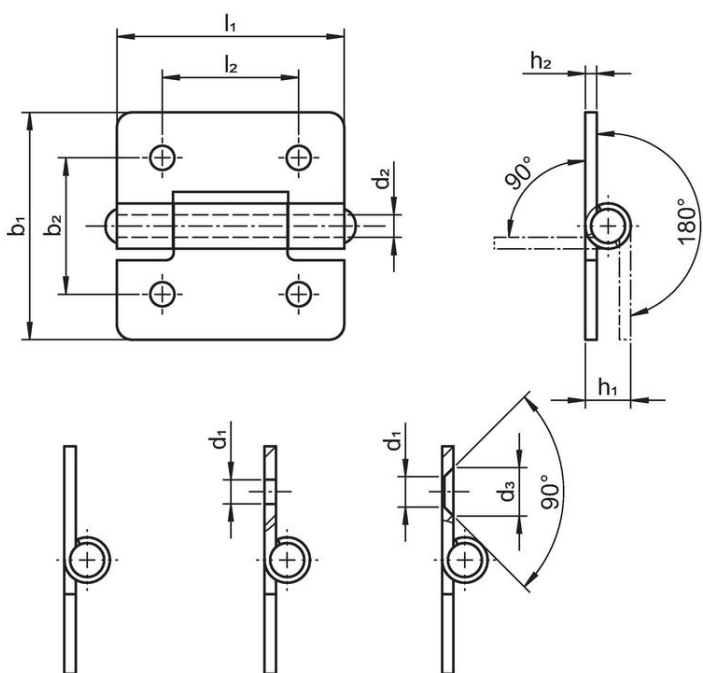

Afbeelding 1 Afbeelding 2 Afbeelding 3

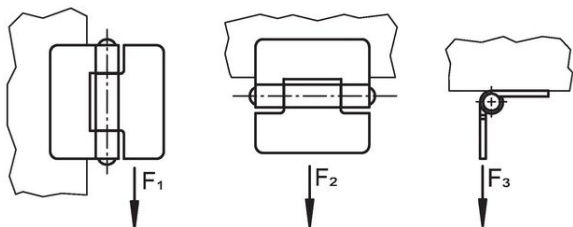

Bestelinformatie

Afmetingen									Klemkracht			[g]	Artikelnr.
b ₁	l ₁	b ₂	d ₁	d ₂	d ₃	h ₁	h ₂	l ₂	F ₁	F ₂	F ₃		
[mm]									~	~	~		
									~	[N]			
with bores for countersunk screws – Afbeelding 3, Staal													
30	30	18	4	3	6,4	6	1,5	18	700	500	500	15	25165.2015

Voldoet

Conform RoHS

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC stoffen

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 27.06.2024.

Bevat geen propositie 65 stoffen

Geen propositie 65 stoffen inbegrepen
<https://www.P65Warnings.ca.gov/>

Vrij van conflictmineralen

Dit product bevat geen stoffen die worden aangeduid als "conflictmineralen" zoals tantaal, tin, goud of wolfrام uit de Democratische Republiek Congo of aangrenzende landen."