

Scharnieren • elongated on one side

EH 25165.



Productbeschrijving

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Materiaal


Huls

- RVS 1.4301
- staal, verzinkt door galvanisatie, gepassiveerd

As

- RVS 1.4301


Tekening

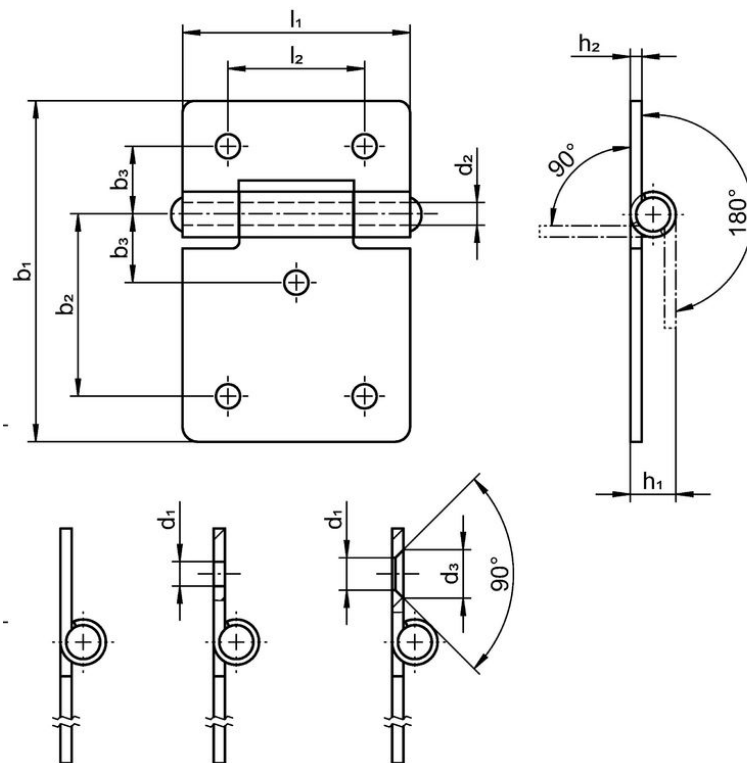


picture 1

picture 2

picture 3

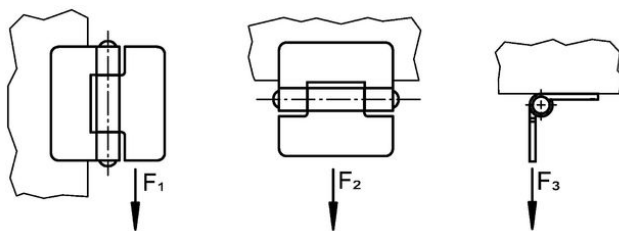

Bestelinformatie

| b ₁ | l ₁ | b ₂ | b ₃ | Afmetingen | | | | | | Klemkracht | | |  | Artikelnr. |
|--|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|---|----------------------------|
| | | | | d ₁ | d ₂ | d ₃ | h ₁ | h ₂ | l ₂ | F ₁ | F ₂ | F ₃ | | |
| [mm] | | | | | | | | | | [N] | | | [g] | |
| without bores – Afbeelding 1, Roestvast staal | | | | | | | | | | | | | | |
| 45 | 30 | – | – | – | 3 | – | 6 | 1,5 | – | 700 | 500 | 450 | 20 | 25165.0035 |
| 60 | 40 | – | – | – | 4 | – | 8 | 2,0 | – | 1200 | 1000 | 1000 | 47 | 25165.0055 |
| 75 | 50 | – | – | – | 6 | – | 10 | 2,0 | – | 1600 | 2000 | 1000 | 81 | 25165.0070 |
| 90 | 60 | – | – | – | 6 | – | 10 | 2,0 | – | 1100 | 2500 | 1000 | 111 | 25165.0080 |
| with bores – Afbeelding 2, Roestvast staal | | | | | | | | | | | | | | |
| 45 | 30 | 24,0 | 9,0 | 3,2 | 3 | – | 6 | 1,5 | 18 | 700 | 500 | 450 | 19 | 25165.0135 |
| 60 | 40 | 32,5 | 12,5 | 4,2 | 4 | – | 8 | 2,0 | 18 | 1200 | 1000 | 1000 | 45 | 25165.0155 |
| 75 | 50 | 40,0 | 15,0 | 5,2 | 6 | – | 10 | 2,0 | 30 | 1600 | 2000 | 1000 | 79 | 25165.0170 |
| 90 | 60 | 48,0 | 18,0 | 5,2 | 6 | – | 10 | 2,0 | 36 | 1100 | 2500 | 1000 | 108 | 25165.0180 |
| with bores – Afbeelding 2, Staal | | | | | | | | | | | | | | |
| 45 | 30 | 24,0 | 9,0 | 3,2 | 3 | – | 6 | 1,5 | 18 | 700 | 500 | 450 | 19 | 25165.1035 |
| 60 | 40 | 32,5 | 12,5 | 4,2 | 4 | – | 8 | 2,0 | 25 | 1200 | 1000 | 1000 | 45 | 25165.1055 |
| 75 | 50 | 40,0 | 15,0 | 5,2 | 6 | – | 10 | 2,0 | 30 | 1600 | 2000 | 1000 | 79 | 25165.1070 |
| 90 | 60 | 48,0 | 18,0 | 5,2 | 6 | – | 10 | 2,0 | 36 | 1100 | 2500 | 1000 | 108 | 25165.1080 |
| with bores for countersunk screws – Afbeelding 3, Roestvast staal | | | | | | | | | | | | | | |
| 45 | 30 | 24,0 | 9,0 | 4,0 | 3 | 6,4 | 6 | 1,5 | 18 | 700 | 500 | 450 | 19 | 25165.0235 |
| 60 | 40 | 32,5 | 12,5 | 5,0 | 4 | 8,3 | 8 | 2,0 | 25 | 1200 | 1000 | 1000 | 45 | 25165.0255 |
| 75 | 50 | 40,0 | 15,0 | 5,0 | 6 | 8,3 | 10 | 2,0 | 30 | 1600 | 2000 | 1000 | 79 | 25165.0270 |
| 90 | 60 | 48,0 | 18,0 | 5,0 | 6 | 8,3 | 10 | 2,0 | 36 | 1100 | 2500 | 1000 | 108 | 25165.0280 |
| with bores for countersunk screws – Afbeelding 3, Staal | | | | | | | | | | | | | | |
| 45 | 30 | 24,0 | 9,0 | 4,0 | 3 | 6,4 | 6 | 1,5 | 18 | 700 | 500 | 450 | 19 | 25165.2035 |
| 60 | 40 | 32,5 | 12,5 | 5,0 | 4 | 8,3 | 8 | 2,0 | 25 | 1200 | 1000 | 1000 | 45 | 25165.2055 |
| 75 | 50 | 40,0 | 15,0 | 5,0 | 6 | 8,3 | 10 | 2,0 | 30 | 1600 | 2000 | 1000 | 79 | 25165.2070 |
| 90 | 60 | 48,0 | 18,0 | 5,0 | 6 | 8,3 | 10 | 2,0 | 36 | 1100 | 2500 | 1000 | 108 | 25165.2080 |

Voldoet

Conform RoHS

Voldoet aan Richtlijn 2011/65/EU en richtlijn 2015/863

Bevat geen SVHC stoffen

Bevat geen SVHC-stoffen met meer dan 0,1% w/w - SVHC-lijst per 23.01.2024.

Bevat geen propositie 65 stoffen

Geen propositie 65 stoffen inbegrepen

<https://www.P65Warnings.ca.gov/>

Vrij van conflictmineralen

Dit product bevat geen stoffen die worden aangeduid als "conflictmineralen" zoals tantaal, tin, goud of wolfram uit de Democratische Republiek Congo of aangrenzende landen."