

Płaskie nakrętki radełkowane • DIN 467

24760.0512



Opis produktu

Knurled nuts are very versatile. Three material versions for the different requirements

- Steel, blackened
- Steel, zinc-plated by galvanization
- Stainless steel

are available.

Knurled nuts can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

The flat knurled nuts are manufactured according to DIN 467.

Materiał

- stal, cynkowane galwanicznie, jakość 5

Więcej informacji


Uwagi

Skok i głębokość radełkowania mogą różnić się od DIN.


Inne produkty

- Nakrętki wysokie radełkowane (z kołnierzem), DIN 466

Rysunek

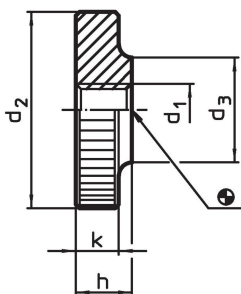

Informacje do zamówienia

| d_1 | d_2 | Wymiary d_3 [mm] | h | k |  [g] | Nr art. ¹⁾ |
|-------|-------|--------------------------|-----|-----|--|-----------------------|
| Stal | | | | | | |
| M12 | 40 | 22 | 12 | 10 | 92 | 24760.0512 |

¹⁾ Wymiar nie jest ujęty w normie DIN.

Przykład aplikacji



Zgodność

Zgodny z RoHS

Zgodny zgodnie z Dyrektywą 2011/65/UE i Dyrektywą 2015/863

Nie zawiera substancji SVHC

Brak substancji SVHC o zawartości powyżej 0,1% mas. – lista SVHC z 27.06.2024.

Nie zawiera substancji Propozycji 65

Nie zawiera substancji z rozporządzenia Proposition 65.

<https://www.P65Warnings.ca.gov/>

Wolny od minerałów konfliktu

Ten produkt nie zawiera żadnych substancji oznaczonych jako „minerały konfliktu”, takich jak tantal, cyna, złoto lub wolfram z Demokratycznej Republiki Konga lub krajów sąsiednich.