

## Płaskie śruby radełkowane • DIN 653

24770.0176



## Opis produktu

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

Śruby radełkowane wykonane są z jednego elementu, z gwintem do 1ba (oznaczenie DIN: A).

## Materiał

- Stal oksydowana, jakość 5.8

## Więcej informacji


## Uwagi

Skok i głębokość radełkowania mogą różnić się od DIN.

## Inne produkty

- Śruby wysokie radełkowane, DIN 464

## Rysunek

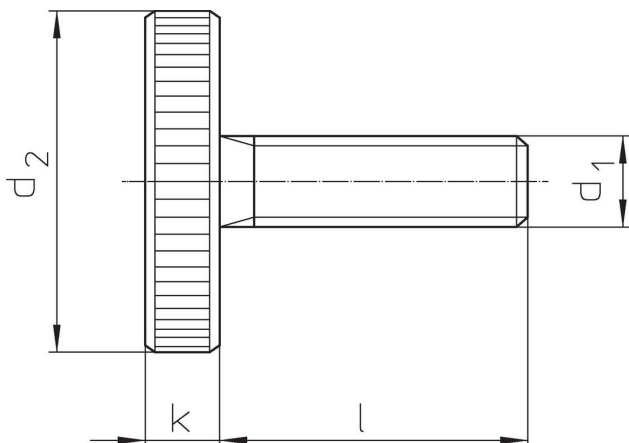

## Informacje do zamówienia

d <sub>1</sub>	Wymiary			[g]	Nr art.
	l	d <sub>2</sub>	k		
[mm]					
Stal					
M10	30	36	8	76	24770.0176

## Zgodność

## Zgodny z RoHS

Zawiera ołów - zgodny z wyjątkami 6a /6b /6c

## Zawiera substancje SVHC &gt; 0,1% mas.

Zawiera ołów – lista SVHC [REACH] z dnia 27.06.2024.

## Zawiera substancje z Propozycja 65



Kontakt z ołowiem może powodować raka i bezpłodność  
<https://www.P65Warnings.ca.gov/>

## Wolny od minerałów konfliktu

Ten produkt nie zawiera żadnych substancji oznaczonych jako „minerały konfliktu”, takich jak tantal, cyna, złoto lub wolfram z Demokratycznej Republiki Konga lub krajów sąsiednich.