

Płaskie śruby radełkowane • DIN 653

24770.0180



Opis produktu

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

Śruby radełkowane wykonane są z jednego elementu, z gwintem do 1ba (oznaczenie DIN: A).

Materiał

- Stal oksydowana, jakość 5.8

Więcej informacji


Uwagi

Skok i głębokość radełkowania mogą różnić się od DIN.

Inne produkty

- Śruby wysokie radełkowane, DIN 464

Rysunek

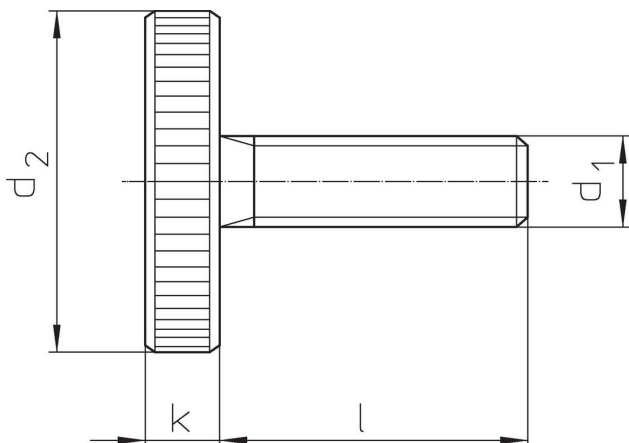

Informacje do zamówienia

| d ₁ | Wymiary | | | [g] | Nr art. |
|----------------|---------|----------------|---|-----|------------|
| | l | d ₂ | k | | |
| [mm] | | | | | |
| Stal | | | | | |
| M10 | 40 | 36 | 8 | 80 | 24770.0180 |

Zgodność

Zgodny z RoHS

Zawiera ołów - zgodny z wyjątkami 6a /6b /6c

Zawiera substancje SVHC > 0,1% mas.

Zawiera ołów – lista SVHC [REACH] z dnia 27.06.2024.

Zawiera substancje z Propozycja 65



Kontakt z ołowiem może powodować raka i bezpłodność
<https://www.P65Warnings.ca.gov/>

Wolny od minerałów konfliktu

Ten produkt nie zawiera żadnych substancji oznaczonych jako „minerały konfliktu”, takich jak tantal, cyna, złoto lub wolfram z Demokratycznej Republiki Konga lub krajów sąsiednich.