

Gałki EH 24520.




Opis produktu


Materiał

- Stal oksydowana
- Stal nierdzewna 1.4305, piaskowana


Rysunek

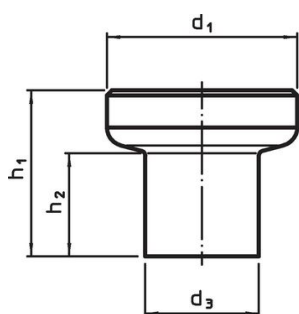

Rysunek 1

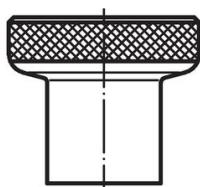


Rysunek 2

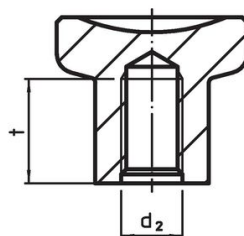


Informacje do zamówienia

d ₁	d ₂	d ₃	Wymiary				t min.	[g]	Nr art.
			[mm]						
gładka – rysunek 1, Stal									
21	M 4	12,5	18,0	10,5	10	26	24520.0002		
21	M 5	12,5	18,0	10,5	10	25	24520.0003		
25	M 6	14,5	22,5	14,0	12	42	24520.0005		
25	M 8	14,5	22,5	14,0	12	38	24520.0006		
31	M 8	18,5	27,0	17,0	15	75	24520.0008		
31	M10	18,5	27,0	17,0	17	70	24520.0009		
radelkowana – rysunek 2, Stal									
21	M 4	12,5	18,0	10,5	10	26	24520.0022		
21	M 5	12,5	18,0	10,5	10	25	24520.0023		
25	M 6	14,5	22,5	14,0	12	42	24520.0025		
25	M 8	14,5	22,5	14,0	12	39	24520.0026		
31	M 8	18,5	27,0	17,0	15	75	24520.0028		
31	M10	18,5	27,0	17,0	17	70	24520.0029		
gładka – rysunek 1, Stal nierdzewna									
21	M 4	12,5	18,0	10,5	10	26	24520.0102		
21	M 5	12,5	18,0	10,5	10	25	24520.0103		
25	M 6	14,5	22,5	14,0	12	42	24520.0105		
25	M 8	14,5	22,5	14,0	12	38	24520.0106		
31	M 8	18,5	27,0	17,0	15	75	24520.0108		
31	M10	18,5	27,0	17,0	17	70	24520.0109		

d ₁	d ₂	d ₃	Wymiary			t min.	 [g]	Nr art.
			[mm]					
radełkowana – rysunek 2, Stal nierdzewna								
21	M 4	12,5	18,0	10,5	10	26	24520.0122	
21	M 5	12,5	18,0	10,5	10	25	24520.0123	
25	M 6	14,5	22,5	14,0	12	42	24520.0125	
25	M 8	14,5	22,5	14,0	12	39	24520.0126	
31	M 8	18,5	27,0	17,0	15	75	24520.0128	
31	M10	18,5	27,0	17,0	17	70	24520.0129	

Przykład aplikacji

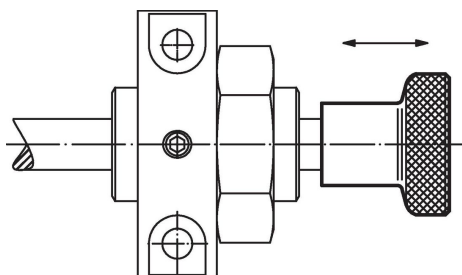

Zgodność

Dla szczegółowych informacji dot. zgodności należy wybrać pożądany numer towaru.