


FOR OUTDOOR

MAINTENANCE WORK

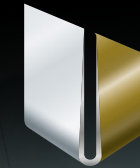

**HALDER**



german  
brand  
award  
19  
gold



**SUPERCRAFT SLEDGE  
SERIES 3366.VS**

- **Non-rebound, high impact**
- Safe alternative to hitting steel on steel
- Vibration-reducing Hickory handle
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art.-No.	∅ [mm]	[g]	[mm]
3366.081	80	4.410	880
3366.107	100	7.050	1.000
3366.110	100	9.300	1.000



**SUPERCRAFT SERIES 3377.1**

- **Non-rebound, high impact**
- Safe alternative to hitting steel on steel
- Break-proof steel tube handle and fluorescent yellow powder coating
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art.-No.	∅ [mm]	[g]	[mm]
3377.140	40	805	305
3377.150	50	1.150	315
3377.160	60	1.750	325

**ERWIN HALDER KG**

Erwin-Halder-Straße 5-9  
88480 Achstetten-Bronnen  
Germany

T +49 7392 7009-0  
F +49 7392 7009-160  
info@halder.com  
www.halder.com

**MALLET BLOCK**

- Hit it: That fits
- For road, walkway and park construction
- Durable, heavy-duty special plastic
- To offset any differences in height

Art.-No.	[mm]	[mm]	[mm]	[g]
3688.001	200	140	40	1.065

Distributed by:

GB/EH/04/2020



103.144




**THE  
ORIGINAL  
FOR PROFESSIONALS**

**CONSTRUCTION / LANDSCAPING  
AND HARDSCAPING**

## PAVER INSTALLATION



## FLOOR TILING / NATURAL STONE SETTING

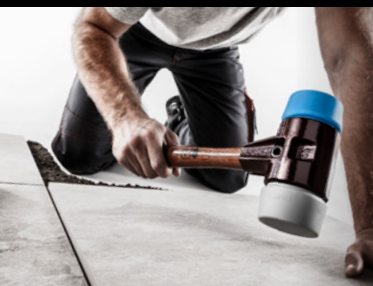

## FLOOR TILING / PAVING OF DELICATE MATERIAL



### SIMPLEX SERIES 3027

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art.-No.	∅ [mm]	[g]	[mm]
3027.050	50	1.105	370
3027.060	60	1.510	405
3027.080	80	2.770	490

### SLEDGE HAMMER SIMPLEX SERIES 3027.VS

- All parts are replaceable
- High quality Hickory handle, high density, long-stranded, very robust
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art.-No.	∅ [mm]	[g]	[mm]
3027.081	80	3.170	800
3027.100	100	5.350	1.000

### SIMPLEX SERIES 3013

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / TPE-mid (grey, medium hard, **non-marring**)

Art.-No.	∅ [mm]	[g]	[mm]
3013.050	50	1.060	370
3013.060	60	1.420	405

### SIMPLEX SERIES 3012

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness)

Art.-No.	∅ [mm]	[g]	[mm]
3012.050	50	1.095	370
3012.060	60	1.480	405

### SIMPLEX SERIES 3113

- Extremely lightweight aluminium housing
- All parts are replaceable
- High quality wood handle
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / TPE-mid (grey, medium hard, **non-marring**)

Art.-No.	∅ [mm]	[g]	[mm]
3113.050	50	635	370
3113.060	60	850	405

### SIMPLEX SERIES 3137

- Extremely lightweight aluminium housing
- All parts are replaceable
- High quality wood handle
- 2 different inserts: TPE-mid (grey, medium hard, **non-marring**) / Superplastic (white, medium hard, very durable, wear-resistant)

Art.-No.	∅ [mm]	[g]	[mm]
3137.050	50	645	370
3137.060	60	875	405