

Șuruburi plate molețate • DIN 653

24770.0294



Descrierea produsului

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

Toate șuruburile molețate sunt produse dintr-o singură bucată cu filet până la cap (Clasa DIN A).

Material

- Oțel inoxidabil 1.4305, sablare mată

Mai multe informații


Note

Înclinația filetelui sau adâncimea poate să difere față de standardul DIN.

Produse asociate

- Șuruburi molețate înalte, DIN 464

Desen

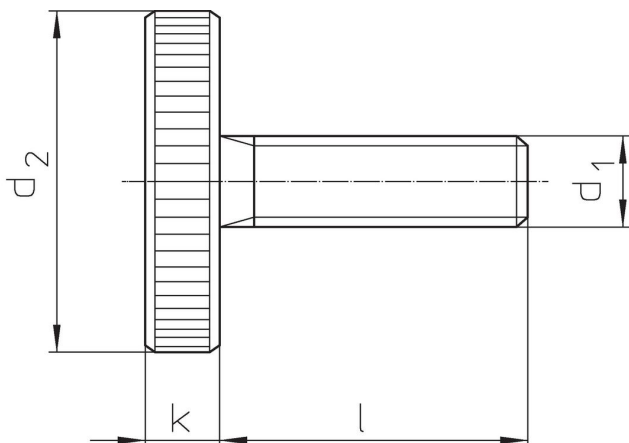

Informații comandă

| d ₁ | l | Dimensiuni | | k | [g] | Ref. Nr. |
|------------------------|----|----------------|------|-----|-----|------------|
| | | d ₂ | [mm] | | | |
| Oțel inoxidabil | | | | | | |
| M4 | 12 | 16 | | 3,5 | 6,1 | 24770.0294 |

Reclamație

Conform RoHS

Sunt conforme Directivei 2011/65/UE și Directivei 2015/863.

Nu conține materiale SVHC

Nu conține substanțe SVHC cu mai mult de 0,1% w/w - lista SVHC din 27.06.2024.

Nu conține substanțe din Declarația 65

Nu conține substanțe din Declarația 65.

<https://www.P65Warnings.ca.gov/>

Nu conține Minerale de conflict

Acest produs nu conține substanțe desemnate drept „minerale de conflict” precum tantalul, staniul, aurul sau wolfram din Republica Democratică Congo sau din țările adiacente.