

## Șuruburi plate molețate • DIN 653

24770.0312



## Descrierea produsului

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

Toate șuruburile molețate sunt produse dintr-o singură bucată cu filet până la cap (Clasa DIN A).

## Material

- Oțel inoxidabil 1.4305, sablare mată

## Mai multe informații


## Note

Înclinația filetelui sau adâncimea poate să difere față de standardul DIN.

## Produse asociate

- Șuruburi molețate înalte, DIN 464

## Desen

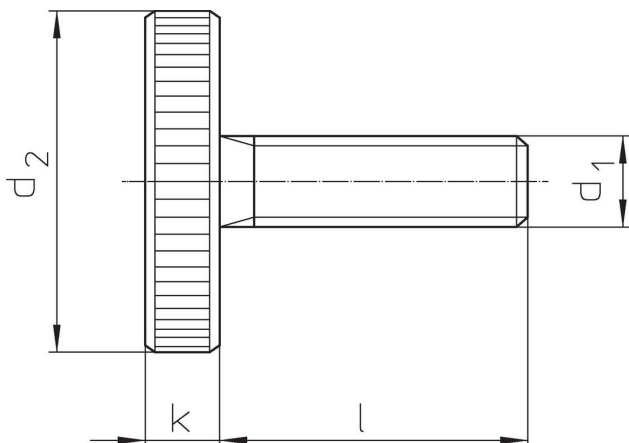

## Informații comandă

d <sub>1</sub>	Dimensiuni		d <sub>2</sub>	k	[g]	Ref. Nr.
	l	[mm]				
<b>Oțel inoxidabil</b>						
M5	10		20	4	10	24770.0312

## Reclamație

## Conform RoHS

Sunt conforme Directivei 2011/65/UE și Directivei 2015/863.

## Nu conține materiale SVHC

Nu conține substanțe SVHC cu mai mult de 0,1% w/w - lista SVHC din 27.06.2024.

## Nu conține substanțe din Declarația 65

Nu conține substanțe din Declarația 65.

<https://www.P65Warnings.ca.gov/>

## Nu conține Minerale de conflict

Acest produs nu conține substanțe desemnate drept „minerale de conflict” precum tantalul, staniul, aurul sau wolfram din Republica Democratică Congo sau din țările adiacente.