

Butoane sferice · variantă metalică similar DIN 319 EH 24561.



Descrierea produsului

Material


- Oțel, polizat, lucios
- Oțel inoxidabil 1.4305, sablare mată
- Aluminiu, lucios

Mai multe informații

Note

Completarea Forma C DIN 319 cu varianta din metal.


Desen

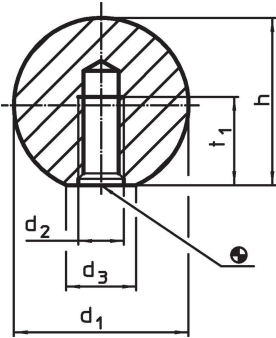

Informații comandă

d ₁	d ₂	Dimensiuni		t ₁ min.	[g]	Ref. Nr.
		d ₃ ~ [mm]	h ~			
Oțel						
16	M 4	8	15,0	7,0	16	24561.0016
20	M 5	12	18,0	9,0	26	24561.0020
25	M 6	15	22,5	11,0	58	24561.0025
32	M 8	18	29,0	14,5	116	24561.0032
40	M10	22	37,0	18,0	241	24561.0040
50	M12	27	46,0	21,0	475	24561.0050
Oțel inoxidabil						
16	M 4	8	15,0	7,0	16	24561.0216
20	M 5	12	18,0	9,0	26	24561.0220
25	M 6	15	22,5	11,0	58	24561.0225
32	M 8	18	29,0	14,5	116	24561.0232
40	M10	22	37,0	18,0	241	24561.0240
Aluminiu Al						
16	M 4	8	15,0	7,0	16	24561.0116
20	M 5	12	18,0	9,0	26	24561.0120
25	M 6	15	22,5	11,0	58	24561.0125
32	M 8	18	29,0	14,5	116	24561.0132
40	M10	22	37,0	18,0	241	24561.0140
50	M12	27	46,0	21,0	475	24561.0150

Exemplu de aplicație

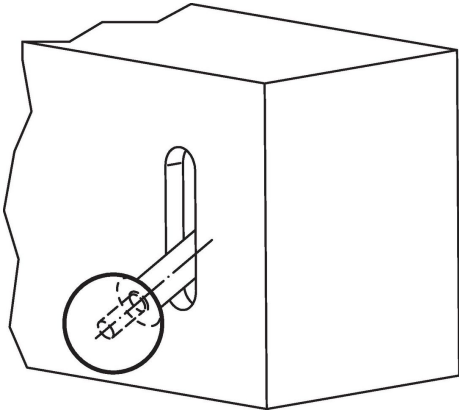

Reclamație

Pentru detalii suplimentare despre conformitate, vă rugăm să selectați codul produsului dorit.