

Gångjärn • elongated on one side

25165.0270



Produktbeskrivning

The different versions cover many applications that require a low load.

These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

Material


Kropp

- Rostfritt stål 1.4301


Axlig

- Rostfritt stål 1.4301

Ritning

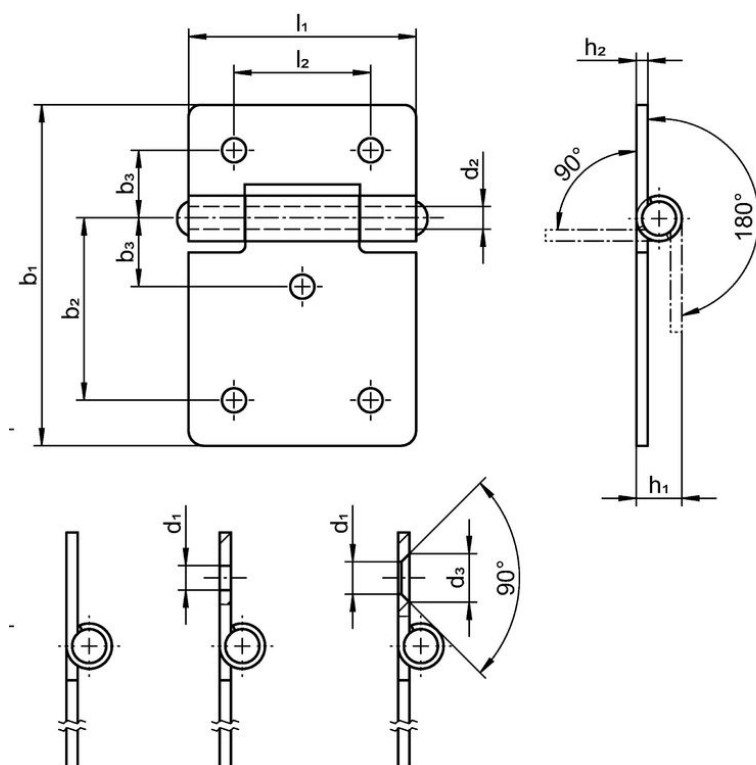

picture 1 picture 2 picture 3

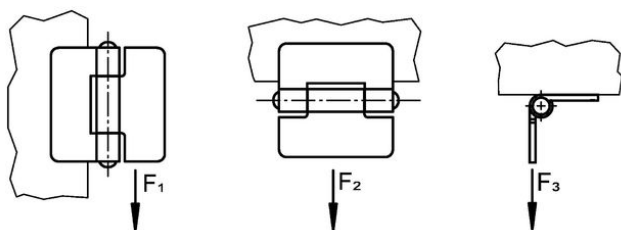

Orderinformation

b ₁	l ₁	b ₂	b ₃	Dimension						Hållkraft			Art.nr.	
				d ₁	d ₂	d ₃	h ₁	h ₂	l ₂	F ₁	F ₂	F ₃		
[mm]										~	~	~	[g]	
with bores for countersunk screws – Bild 3, rostfritt stål														
75	50	40	15	5	6	8,3	10	2	30	1600	2000	1000	79	25165.0270

Överensstämmelse

RoHS-kompatibel

Överensstämmer med direktiv 2011/65/EU och direktiv 2015/863

Innehåller inte SVHC-ämnen

Inga SVHC-ämnen med mer än 0,1 % w/w - SVHC-lista [REACH] per 23.01.2024.

Innehåller inte ämnen i proposition 65

Inga Proposition 65-ämnen inkluderade

<https://www.P65Warnings.ca.gov/>

Fri från konfliktmineraler

Denna produkt innehåller inga ämnen betecknade som konfliktmineraler" såsom tantal, tenn, guld eller volfram från Demokratiska republiken Kongo eller angränsande länder."