

Handtag · DIN 39
EH 24450.



Produktbeskrivning

Material

- Stål, svarvad, förzinkad genom galvanisering, passiverad
- Rostfritt stål 1.4404

Ritning

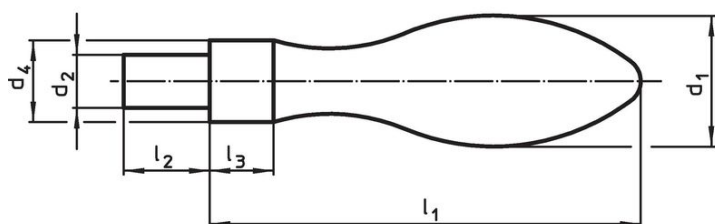


Bild 1

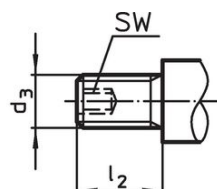


Bild 2


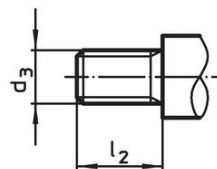


Bild 3

Orderinformation

d ₁	d ₂ h8	d ₃	Dimension				SW	[g]	Art.nr.
			d ₄ h13 [mm]	l ₁ ~	l ₂	l ₃			
Med ogängad tapp, form D – Bild 1, stål									
16	7	–	10	50	11	7	–	45	24450.0016
20	8	–	13	64	13	8	–	92	24450.0020
25	10	–	16	80	14	10	–	179	24450.0025
32	13	–	20	100	21	13	–	356	24450.0032
36	16	–	22	112	26	14	–	519	24450.0036
Med utvändig gänga, form E – Bild 2, stål									
16	–	M 6	10	50	11	7	3	43	24450.0116
20	–	M 8	13	64	13	8	4	88	24450.0120
25	–	M10	16	80	14	10	5	175	24450.0125
32	–	M12	20	100	21	13	6	340	24450.0132
36	–	M16	22	112	26	14	8	509	24450.0136
Med utvändig gänga, form E – Bild 3, rostfritt stål									
16	–	M 6	10	50	11	7	–	45	24450.0316
20	–	M 8	13	64	13	8	–	92	24450.0320
25	–	M10	16	80	14	10	–	186	24450.0325

Användningsexempel

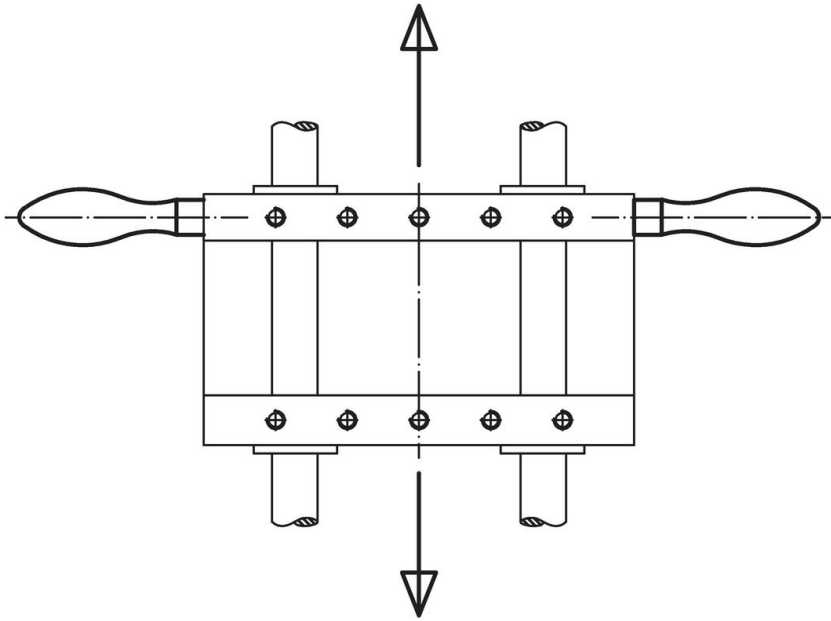

Överensstämmelse

For detailed compliance information please select the desired article number.