

## Räfflad Mutter • plast

### EH 24820.



#### Produktbeskrivning

#### Material


##### Bussning

- Stål, förzinkat genom galvanisering
- Rostfritt stål 1.4305

##### Handtag

- Thermoplast (PA), svart


#### Ritning

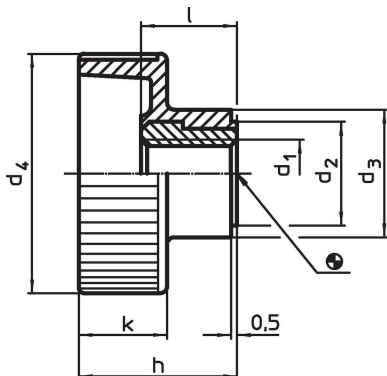

#### Orderinformation

Dimension							🌡️		📦	Art.nr.
d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	d <sub>4</sub>	h	k	l	min.	max.	[g]	
[mm]							[°C]			
<b>Stål</b>										
M 4	9	12	19	14,0	8,0	9,0	-30	80	4,5	<a href="#">24820.0004</a>
M 5	9	12	19	14,0	8,0	9,0	-30	80	4,0	<a href="#">24820.0005</a>
M 6	12	14	24	16,5	9,5	10,5	-30	80	7,0	<a href="#">24820.0006</a>
M 8	14	16	30	19,5	11,0	11,5	-30	80	10,0	<a href="#">24820.0008</a>
M10	16	18	36	22,5	12,5	14,0	-30	80	15,0	<a href="#">24820.0010</a>
<b>Rostfritt stål</b>										
M 5	9	12	19	14,0	8,0	9,0	-30	80	4,0	<a href="#">24820.0205</a>
M 6	12	14	24	16,5	9,5	10,5	-30	80	7,0	<a href="#">24820.0206</a>
M 8	14	16	30	19,5	11,0	11,5	-30	80	10,0	<a href="#">24820.0208</a>

### Användningsexempel

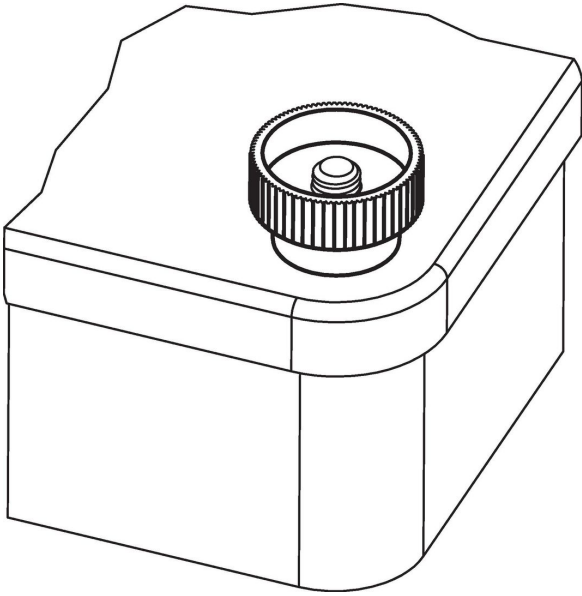

### Överensstämmelse

För detaljerad överensstämmelseinformation, välj önskat artikelnummer.