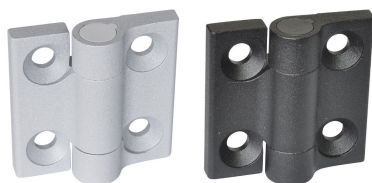


Gångjärn • Zink gjutet  
EH 25163.

## Produktbeskrivning

These hinges from zinc die-cast are characterised by their simple and timeless design.

## Material

## Kropp

- Zink, gjutet, plastbelagd, silver, liknande RAL 9006, matt yta
- Zink, gjutet, plastbelagd, svart, liknande RAL 9005, matt yta

## Täcka


- Thermoplast (POM)

## Mer information

## Ytterligare produkter

- Distansplattor, till gångjärn
- Gängade plattor, till gångjärn

## Ritning

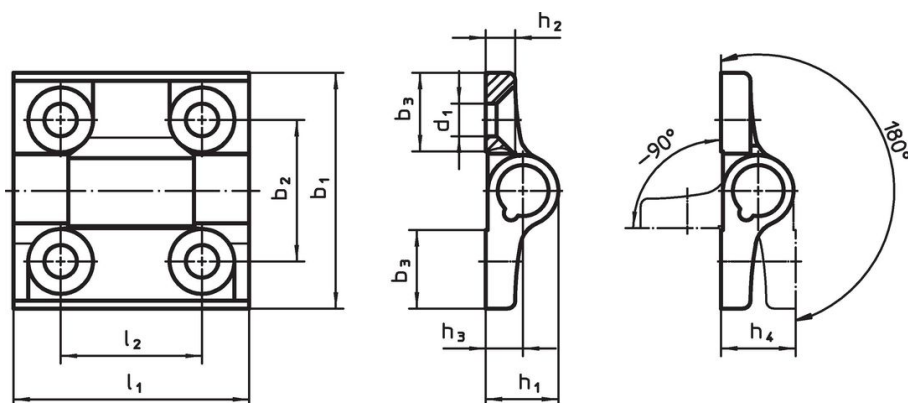

## Orderinformation

Dimension											max. [°C]	[g]	Art.nr.		
b <sub>1</sub>	l <sub>1</sub>	b <sub>2</sub>	b <sub>3</sub>	d <sub>1</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	h <sub>4</sub>	l <sub>2</sub>	[mm]					
Zink gjutet, silver															
60	60	36	20	8,3	18,5	7,5	9,5	19	36		80	137	25163.0005		
Zink gjutet, svart															
60	60	36	20	8,3	18,5	7,5	9,5	19	36		80	137	25163.0105		

## Överensstämmelse

For detailed compliance information please select the desired article number.