

Spring Push Plungers · 附水平或螺絲凸緣

22170.1110

產品描述



The spring push plungers are used for simple and secure positioning of workpieces or components on stops and support points.

The spring push plunger is designed with a thrust pad that can be rotated 4 x 90° depending on the application.

Below h_2 , a pull-down effect is created when the thrust pad is installed in the appropriate position.

材質

本體

- 鋅合金壓鑄、塑料塗層、黑色，近似RAL 9005亞光結構

止推墊

- 不鏽鋼1.4542

螺絲

- 不鏽鋼 A2


彈簧

- 不銹鋼 1.4310

組裝

通過墊圈ISO 7092進行組裝。

圖面

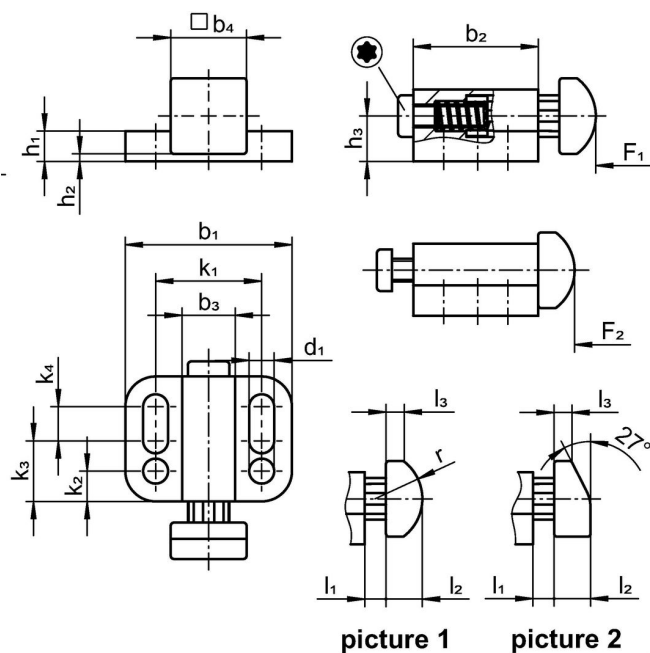

訂單資訊

| 尺寸 | | | | | | | | | | | | | | | 行程 s [mm] | 彈簧荷重 ¹⁾ F ₁ F ₂ [N] | 品號 | | | |
|--|----------------|----------------|----------------|----------------|----------------|------------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----------------|--|----|-----|----|------------|
| b ₁ | d ₁ | b ₂ | b ₃ | b ₄ | h ₁ | h ₂ +0,5 | h ₃ | k ₁ | k ₂ | k ₃ | k ₄ | l ₁ | l ₂ | l ₃ | | | | [g] | | |
| plunger wedge-shaped, reinforced spring load – 相片 2, 不銹鋼 | | | | | | | | | | | | | | | | | | | | |
| 32 | 5,4 | 27,5 | 10 | 16 | 5 | 1 | 9 | 21 | 5,5 | 12 | 10 | 5 | 7 | 3,1 | 5 | 20 | 19 | 45 | 40 | 22170.1110 |

¹⁾ 統計平均值

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物質

不含超過 0.1% w/w 的 SVHC 物質 - 截至 2024 年 1 月 23 日的 SVHC 清單。

不含 65 號提案物質

不包括 65 號提案物質

<https://www.P65Warnings.ca.gov/>

不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈿、錫、金或鎳。