

平壓花姆指螺帽 · DIN 653

24770.0178



產品描述

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

螺紋加工至頭部並帶有跳動，螺紋末端沒有底切 (DIN 名稱 A)。因此螺絲不能擰入到頭部。

材質

- 鋼、染黑、品質 5.8

更多資訊


注意事項

根據 DIN 規範，壓花的間距和深度也不同。

更多產品

- 高壓花的手轉螺絲, DIN 464

圖面

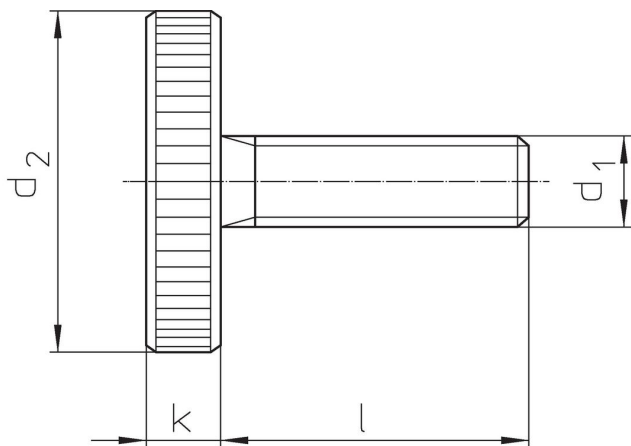

訂單資訊

| d ₁ | 尺寸 l [mm] | d ₂ | k | 品號 |
|----------------|-----------------|----------------|---|------------|
| M10 | 35 | 36 | 8 | 24770.0178 |

遵守

符合 RoHS

含鉛 - 相容除了例外 6a / 6b / 6c.

含有 >0.1% w/w 的 SVHC 物質

含鉛 - SVHC [REACH] 清單截至 2024 年 6 月 27 日

包含 65 號提案的物質



接觸鉛會導致癌症和生殖危害。接觸鎳會導致癌症。

<https://www.P65Warnings.ca.gov/>

不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈹、錫、金或鎢。