


## 平壓花拇指螺帽 · DIN 653

24770.0474

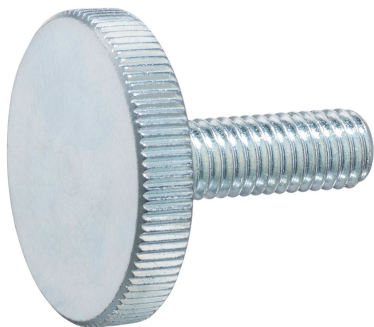

### 產品描述

Knurled thumb screws are very versatile. Three material versions for the different requirements

- steel, blackened
- steel, zinc-plated by galvanization
- stainless steel

are available.

Knurled thumb screws can be easily tightened and released by hand. The ribbed outer surface of the nut prevents slipping when tightening / releasing with the fingers.

螺紋加工至頭部並帶有跳動，螺紋末端沒有底切 (DIN 名稱 A)。因此螺絲不能擰入到頭部。

### 材質

- 鋼，鍍鋅，強度5.8

### 更多資訊


#### 注意事項

根據 DIN 規範，壓花的間距和深度也不同。


#### 更多產品

- 高壓花的手轉螺絲, DIN 464

### 圖面

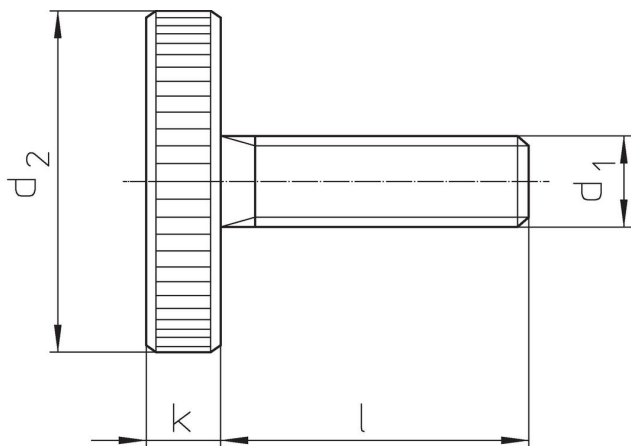

### 訂單資訊

d <sub>1</sub>	l	尺寸 d <sub>2</sub> [mm]	k	 [g]	品號
鋼					
M3	10	12	2,5	3	24770.0474

### 遵守

#### 符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

#### 不含 SVHC 物質

不含超過 0.1% w/w 的 SVHC 物質 - 截至 2024 年 6 月 27 日的 SVHC 清單。

#### 不含 65 號提案物質

不包括 65 號提案物質

<https://www.P65Warnings.ca.gov/>

#### 不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈿、錫、金或鎢。