

活節螺栓 · DIN 444, 型式 B EH 22980.



產品描述

活節螺栓類似於DIN 444，利用更高品質8.8的鋼材設計。不銹鋼A2-50的設計的張力至少 $_{500}N/m^2$ 。

材質

- 熱處理鋼，quality 8.8，黑色
- 不銹鋼 1.4301

更多資訊

注意事項

特殊的樣式歡迎洽詢。


參考

有關起始扭力請參考附件 - 技術資料 -

更多產品


- 活節螺栓, DIN 444, 形式B, quality 8.8

圖面

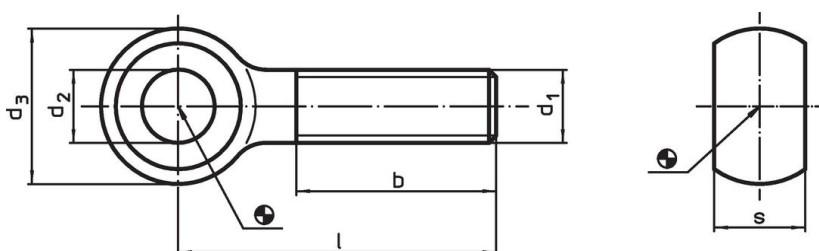

訂單資訊

d ₁	l	尺寸			b	s	[g]	品號
		d ₂ H9 [mm]	d ₃					
熱處理鋼								
M 5	25	5	12	16	6	5,6	22980.0202	
M 5	30	5	12	16	6	6,4	22980.0203	
M 5	35	5	12	16	6	7,1	22980.0204	
M 5	40	5	12	16	6	7,9	22980.0205	
M 6	30	6	14	18	7	9,5	22980.0212	
M 6	40	6	14	18	7	11,0	22980.0214	
M 6	50	6	14	18	7	14,0	22980.0216	
M 6	60	6	14	18	7	16,0	22980.0218	
M 6	80	6	14	18	7	20,0	22980.0222	
M 8	40	8	18	22	9	22,0	22980.0232	
M 8	50	8	18	22	9	26,0	22980.0234	
M 8	60	8	18	22	9	30,0	22980.0236	
M 8	80	8	18	22	9	37,0	22980.0240	
M 8	100	8	18	22	9	44,0	22980.0244	
M10	50	10	20	26	12	40,0	22980.0252	
M10	60	10	20	26	12	43,0	22980.0254	
M10	75	10	20	26	12	51,0	22980.0257	
M10	100	10	20	26	12	67,0	22980.0262	
M10	120	10	20	26	12	72,0	22980.0266	
M12	50	12	25	30	14	59,0	22980.0272	
M12	60	12	25	30	14	68,0	22980.0274	
M12	80	12	25	30	14	85,0	22980.0278	
M12	100	12	25	30	14	102,0	22980.0282	
M12	120	12	25	30	14	119,0	22980.0286	
M16	60	16	32	38	17	128,0	22980.0292	
M16	80	16	32	38	17	159,0	22980.0294	
M16	100	16	32	38	17	190,0	22980.0298	
M16	120	16	32	38	17	220,0	22980.0302	

d ₁	l	尺寸				s		品號
		d ₂ H9 [mm]	d ₃	b	[g]			
M16	150	16	32	44	17	265,0	22980.0308	
M20	100	18	40	46	22	323,0	22980.0312	
M20	120	18	40	46	22	373,0	22980.0316	
M20	160	18	40	52	22	466,0	22980.0324	
M20	200	18	40	52	22	562,0	22980.0332	
M24	100	22	45	54	25	443,0	22980.0342	
M24	120	22	45	54	25	512,0	22980.0346	
M24	160	22	45	60	25	649,0	22980.0354	
M24	200	22	45	60	25	787,0	22980.0362	
不銹鋼								
M 5	25	5	12	16	6	5,6	22980.0402	
M 5	30	5	12	16	6	6,4	22980.0403	
M 5	35	5	12	16	6	7,1	22980.0404	
M 5	40	5	12	16	6	7,9	22980.0405	
M 6	30	6	14	18	7	9,5	22980.0412	
M 6	40	6	14	18	7	11,0	22980.0414	
M 6	50	6	14	18	7	14,0	22980.0416	
M 6	60	6	14	18	7	16,0	22980.0418	
M 6	80	6	14	18	7	20,0	22980.0422	
M 8	40	8	18	22	9	22,0	22980.0432	
M 8	50	8	18	22	9	26,0	22980.0434	
M 8	60	8	18	22	9	30,0	22980.0436	
M 8	80	8	18	22	9	37,0	22980.0440	
M 8	100	8	18	22	9	44,0	22980.0444	
M10	50	10	20	26	12	40,0	22980.0452	
M10	60	10	20	26	12	43,0	22980.0454	
M10	75	10	20	26	12	51,0	22980.0457	
M10	100	10	20	26	12	67,0	22980.0462	
M10	120	10	20	26	12	72,0	22980.0466	
M12	50	12	25	30	14	59,0	22980.0472	
M12	60	12	25	30	14	68,0	22980.0474	
M12	80	12	25	30	14	85,0	22980.0478	
M12	100	12	25	30	14	102,0	22980.0482	
M12	120	12	25	30	14	119,0	22980.0486	
M16	60	16	32	38	17	128,0	22980.0492	
M16	80	16	32	38	17	159,0	22980.0494	
M16	100	16	32	38	17	190,0	22980.0498	
M16	120	16	32	38	17	220,0	22980.0502	
M16	150	16	32	44	17	265,0	22980.0508	
M20	100	18	40	46	22	323,0	22980.0512	
M20	120	18	40	46	22	373,0	22980.0516	
M20	160	18	40	52	22	466,0	22980.0524	
M20	200	18	40	52	22	562,0	22980.0532	
M24	100	22	45	54	25	443,0	22980.0542	
M24	120	22	45	54	25	512,0	22980.0546	
M24	160	22	45	60	25	649,0	22980.0554	
M24	200	22	45	60	25	787,0	22980.0562	

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物質

不含超過 0.1% w/w 的 SVHC 物質 - 截至 2024 年 6 月 27 日的 SVHC 清單。

不含 65 號提案物質

不包括 65 號提案物質

<https://www.P65Warnings.ca.gov/>

不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈿、錫、金或鎳。