

調整式把手 · 帶有夾合螺絲

EH 24410.



產品描述

當使用區域受限或需要特定的槓桿位置時，可調式夾緊槓桿具有多種應用。

材質

把手

- 鋅壓鑄，塑料塗裝，橙色 (接近色號 RAL 2004)，無光澤
- 鋅壓鑄，表面塗裝，銀色，類似 RAL 9006，霧面
- 鋅合金壓鑄，塑料塗層，黑色，近似 RAL 9005 亞光結構

內部零件

- 鋼、染黑、品質 5.8

螺絲

- 鋼、染黑、品質 5.8

操作

藉由舉起控制桿，鋸齒脫開。桿可以定位在由鋸齒。在鬆開桿時，細齒將自動重新嚙合。

更多資訊

注意事項

螺絲可以替換。


參考

求頭版本(圖3)可與推力塑膠零件(EH 22570.)組合。

更多產品

- 推力腳座，塑膠

圖面

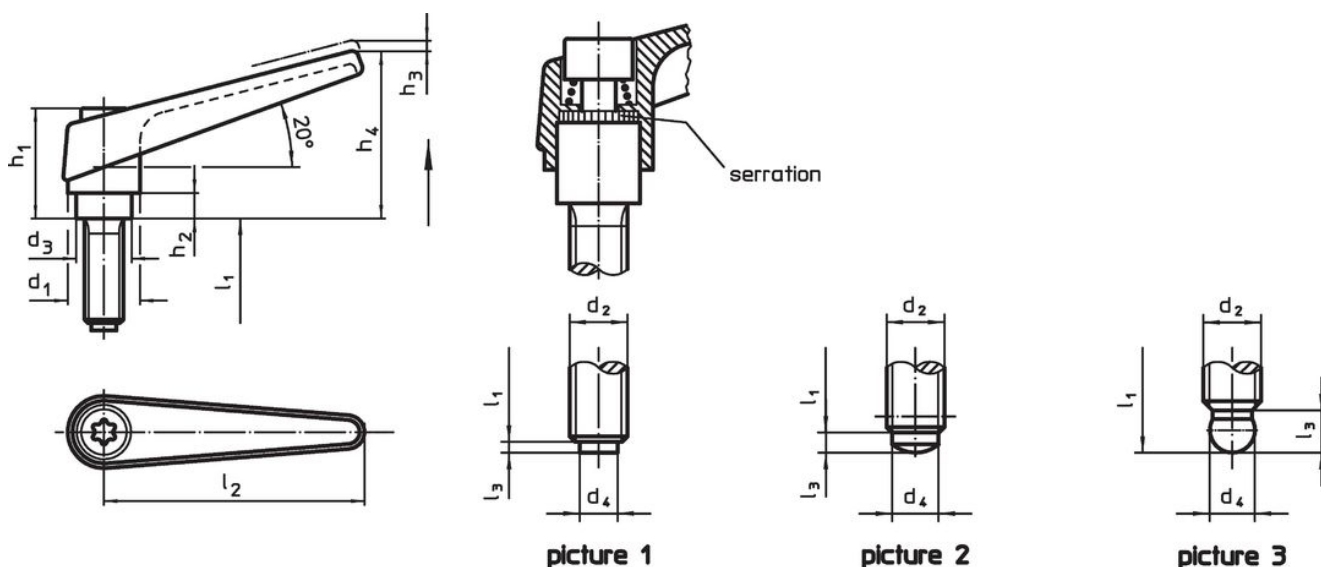

訂單資訊

| 尺寸 | | | | | | | | | | | | [g] | 品號 |
|--------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|------------|----|
| d ₁ | d ₂ | l ₁ | d ₃ | d ₄ | h ₁ | h ₂ | h ₃ | h ₄ | l ₂ | l ₃ | | | |
| [mm] | | | | | | | | | | | | | |
| 帶有塑膠推力銷 - 相片 1, 橘色 | | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0141 | |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0151 | |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0161 | |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0171 | |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 41 | 24410.0181 | |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 45 | 24410.0191 | |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0341 | |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 80 | 24410.0351 | |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 86 | 24410.0361 | |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0371 | |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 84 | 24410.0381 | |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 95 | 24410.0391 | |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 128 | 24410.0441 | |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 130 | 24410.0451 | |

| d ₁ | d ₂ | l ₁ | d ₃ | d ₄ | 尺寸 | | | | | | [g] | 品號 |
|--------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|------------|
| | | | | | h ₁ | h ₂ | h ₃ | h ₄ | l ₂ | l ₃ | | |
| [mm] | | | | | | | | | | | | |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 134 | 24410.0461 |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 94 | 24410.0471 |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 100 | 24410.0481 |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 148 | 24410.0491 |
| 帶有塑膠推力銷 – 相片 1, 銀 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0143 |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0153 |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0163 |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0173 |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 41 | 24410.0183 |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 45 | 24410.0193 |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0343 |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 80 | 24410.0353 |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 86 | 24410.0363 |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0373 |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 84 | 24410.0383 |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 95 | 24410.0393 |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 128 | 24410.0443 |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 130 | 24410.0453 |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 134 | 24410.0463 |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 94 | 24410.0473 |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 100 | 24410.0483 |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 148 | 24410.0493 |
| 帶有塑膠推力銷 – 相片 1, 黑色 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0144 |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0154 |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 38 | 24410.0164 |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 40 | 24410.0174 |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 41 | 24410.0184 |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,0 | 45 | 24410.0194 |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0344 |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 80 | 24410.0354 |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 86 | 24410.0364 |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 81 | 24410.0374 |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 84 | 24410.0384 |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,0 | 95 | 24410.0394 |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 128 | 24410.0444 |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 130 | 24410.0454 |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 134 | 24410.0464 |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 94 | 24410.0474 |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 100 | 24410.0484 |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 2,0 | 148 | 24410.0494 |
| 帶有黃銅推力銷 – 相片 1, 橘色 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 36 | 24410.1141 |
| 14 | M 6 | 20 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 37 | 24410.1151 |
| 14 | M 6 | 25 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 44 | 24410.1161 |
| 14 | M 6 | 32 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 45 | 24410.1171 |
| 14 | M 6 | 40 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 40 | 24410.1181 |
| 14 | M 6 | 50 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 42 | 24410.1191 |
| 18 | M 8 | 20 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 83 | 24410.1341 |
| 18 | M 8 | 25 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 76 | 24410.1351 |
| 18 | M 8 | 32 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 78 | 24410.1361 |
| 18 | M 8 | 40 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 80 | 24410.1371 |
| 18 | M 8 | 50 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 91 | 24410.1381 |
| 18 | M 8 | 63 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 88 | 24410.1391 |
| 18 | M10 | 20 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 127 | 24410.1441 |
| 18 | M10 | 25 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 129 | 24410.1451 |
| 18 | M10 | 32 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 133 | 24410.1461 |
| 18 | M10 | 40 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 137 | 24410.1471 |
| 18 | M10 | 50 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 142 | 24410.1481 |
| 18 | M10 | 63 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 147 | 24410.1491 |

| d ₁ | d ₂ | l ₁ | d ₃ | d ₄ | 尺寸 | | | | | | [g] | 品號 |
|--------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|------------|
| | | | | | h ₁ | h ₂ | h ₃ | h ₄ | l ₂ | l ₃ | | |
| [mm] | | | | | | | | | | | | |
| 帶有黃銅推力銷 – 相片 1, 銀 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 36 | 24410.1143 |
| 14 | M 6 | 20 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 37 | 24410.1153 |
| 14 | M 6 | 25 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 44 | 24410.1163 |
| 14 | M 6 | 32 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 45 | 24410.1173 |
| 14 | M 6 | 40 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 40 | 24410.1183 |
| 14 | M 6 | 50 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 42 | 24410.1193 |
| 18 | M 8 | 20 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 83 | 24410.1343 |
| 18 | M 8 | 25 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 76 | 24410.1353 |
| 18 | M 8 | 32 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 78 | 24410.1363 |
| 18 | M 8 | 40 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 80 | 24410.1373 |
| 18 | M 8 | 50 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 91 | 24410.1383 |
| 18 | M 8 | 63 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 88 | 24410.1393 |
| 18 | M10 | 20 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 127 | 24410.1443 |
| 18 | M10 | 25 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 129 | 24410.1453 |
| 18 | M10 | 32 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 133 | 24410.1463 |
| 18 | M10 | 40 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 137 | 24410.1473 |
| 18 | M10 | 50 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 142 | 24410.1483 |
| 18 | M10 | 63 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 147 | 24410.1493 |
| 帶有黃銅推力銷 – 相片 1, 黑色 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 36 | 24410.1144 |
| 14 | M 6 | 20 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 37 | 24410.1154 |
| 14 | M 6 | 25 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 44 | 24410.1164 |
| 14 | M 6 | 32 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 45 | 24410.1174 |
| 14 | M 6 | 40 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 40 | 24410.1184 |
| 14 | M 6 | 50 | 10,0 | 3,5 | 24,5 | 4,0 | 3 | 35 | 45 | 1,3 | 42 | 24410.1194 |
| 18 | M 8 | 20 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 83 | 24410.1344 |
| 18 | M 8 | 25 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 76 | 24410.1354 |
| 18 | M 8 | 32 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 78 | 24410.1364 |
| 18 | M 8 | 40 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 80 | 24410.1374 |
| 18 | M 8 | 50 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 91 | 24410.1384 |
| 18 | M 8 | 63 | 13,5 | 5,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,3 | 88 | 24410.1394 |
| 18 | M10 | 20 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 127 | 24410.1444 |
| 18 | M10 | 25 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 129 | 24410.1454 |
| 18 | M10 | 32 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 133 | 24410.1464 |
| 18 | M10 | 40 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 137 | 24410.1474 |
| 18 | M10 | 50 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 142 | 24410.1484 |
| 18 | M10 | 63 | 13,5 | 6,5 | 31,0 | 6,5 | 3 | 45 | 62 | 1,9 | 147 | 24410.1494 |
| 帶有推力銷 – 相片 2, 橘色 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 39 | 24410.2141 |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 40 | 24410.2151 |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 41 | 24410.2161 |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 42 | 24410.2171 |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 43 | 24410.2181 |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 45 | 24410.2191 |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 78 | 24410.2341 |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 79 | 24410.2351 |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 81 | 24410.2361 |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 83 | 24410.2371 |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 86 | 24410.2381 |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 91 | 24410.2391 |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 80 | 24410.2441 |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 132 | 24410.2451 |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 136 | 24410.2461 |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 140 | 24410.2471 |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 145 | 24410.2481 |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 150 | 24410.2491 |
| 帶有推力銷 – 相片 2, 銀 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 39 | 24410.2143 |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 40 | 24410.2153 |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 41 | 24410.2163 |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 42 | 24410.2173 |

| d ₁ | d ₂ | l ₁ | d ₃ | 尺寸 | | | | | | | | [g] | 品號 |
|------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|------------|----|
| | | | | d ₄ | h ₁ | h ₂ | h ₃ | h ₄ | l ₂ | l ₃ | | | |
| [mm] | | | | | | | | | | | | | |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 43 | 24410.2183 | |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 45 | 24410.2193 | |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 78 | 24410.2343 | |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 79 | 24410.2353 | |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 81 | 24410.2363 | |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 83 | 24410.2373 | |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 86 | 24410.2383 | |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 91 | 24410.2393 | |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 80 | 24410.2443 | |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 132 | 24410.2453 | |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 136 | 24410.2463 | |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 140 | 24410.2473 | |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 145 | 24410.2483 | |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 150 | 24410.2493 | |
| 帶有推力銷 – 相片 2, 黑色 | | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 39 | 24410.2144 | |
| 14 | M 6 | 20 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 40 | 24410.2154 | |
| 14 | M 6 | 25 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 41 | 24410.2164 | |
| 14 | M 6 | 32 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 42 | 24410.2174 | |
| 14 | M 6 | 40 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 43 | 24410.2184 | |
| 14 | M 6 | 50 | 10,0 | 4,0 | 24,5 | 4,0 | 3 | 35 | 45 | 1,8 | 45 | 24410.2194 | |
| 18 | M 8 | 20 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 78 | 24410.2344 | |
| 18 | M 8 | 25 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 79 | 24410.2354 | |
| 18 | M 8 | 32 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 81 | 24410.2364 | |
| 18 | M 8 | 40 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 83 | 24410.2374 | |
| 18 | M 8 | 50 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 86 | 24410.2384 | |
| 18 | M 8 | 63 | 13,5 | 6,0 | 31,0 | 6,5 | 3 | 45 | 62 | 1,8 | 91 | 24410.2394 | |
| 18 | M10 | 20 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 80 | 24410.2444 | |
| 18 | M10 | 25 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 132 | 24410.2454 | |
| 18 | M10 | 32 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 136 | 24410.2464 | |
| 18 | M10 | 40 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 140 | 24410.2474 | |
| 18 | M10 | 50 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 145 | 24410.2484 | |
| 18 | M10 | 63 | 13,5 | 8,0 | 31,0 | 6,5 | 3 | 45 | 62 | 3,5 | 150 | 24410.2494 | |
| 球形頭 – 相片 3, 橘色 | | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 35 | 24410.3141 | |
| 14 | M 6 | 20 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 36 | 24410.3151 | |
| 14 | M 6 | 25 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 37 | 24410.3161 | |
| 14 | M 6 | 32 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 38 | 24410.3171 | |
| 14 | M 6 | 40 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 39 | 24410.3181 | |
| 14 | M 6 | 50 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 41 | 24410.3191 | |
| 18 | M 8 | 20 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 74 | 24410.3341 | |
| 18 | M 8 | 25 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 75 | 24410.3351 | |
| 18 | M 8 | 32 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 77 | 24410.3361 | |
| 18 | M 8 | 40 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 90 | 24410.3371 | |
| 18 | M 8 | 50 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 82 | 24410.3381 | |
| 18 | M 8 | 63 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 87 | 24410.3391 | |
| 18 | M10 | 20 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 126 | 24410.3441 | |
| 18 | M10 | 25 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 128 | 24410.3451 | |
| 18 | M10 | 32 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 132 | 24410.3461 | |
| 18 | M10 | 40 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 136 | 24410.3471 | |
| 18 | M10 | 50 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 141 | 24410.3481 | |
| 18 | M10 | 63 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 146 | 24410.3491 | |
| 球形頭 – 相片 3, 銀 | | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 35 | 24410.3143 | |
| 14 | M 6 | 20 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 36 | 24410.3153 | |
| 14 | M 6 | 25 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 37 | 24410.3163 | |
| 14 | M 6 | 32 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 38 | 24410.3173 | |
| 14 | M 6 | 40 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 39 | 24410.3183 | |
| 14 | M 6 | 50 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 41 | 24410.3193 | |
| 18 | M 8 | 20 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 74 | 24410.3343 | |
| 18 | M 8 | 25 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 75 | 24410.3353 | |
| 18 | M 8 | 32 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 77 | 24410.3363 | |

| d ₁ | d ₂ | l ₁ | d ₃ | 尺寸 | | | | | | | [g] | 品號 |
|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|------------|
| | | | | d ₄ | h ₁ | h ₂ | h ₃ | h ₄ | l ₂ | l ₃ | | |
| [mm] | | | | | | | | | | | | |
| 18 | M 8 | 40 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 90 | 24410.3373 |
| 18 | M 8 | 50 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 82 | 24410.3383 |
| 18 | M 8 | 63 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 87 | 24410.3393 |
| 18 | M10 | 20 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 126 | 24410.3443 |
| 18 | M10 | 25 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 128 | 24410.3453 |
| 18 | M10 | 32 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 132 | 24410.3463 |
| 18 | M10 | 40 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 136 | 24410.3473 |
| 18 | M10 | 50 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 141 | 24410.3483 |
| 18 | M10 | 63 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 146 | 24410.3493 |
| 球形頭 - 相片 3, 黑色 | | | | | | | | | | | | |
| 14 | M 6 | 16 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 35 | 24410.3144 |
| 14 | M 6 | 20 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 36 | 24410.3154 |
| 14 | M 6 | 25 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 37 | 24410.3164 |
| 14 | M 6 | 32 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 38 | 24410.3174 |
| 14 | M 6 | 40 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 39 | 24410.3184 |
| 14 | M 6 | 50 | 10,0 | 4,5+0,05 | 24,5 | 4,0 | 3 | 35 | 45 | 3,6 | 41 | 24410.3194 |
| 18 | M 8 | 20 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 74 | 24410.3344 |
| 18 | M 8 | 25 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 75 | 24410.3354 |
| 18 | M 8 | 32 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 77 | 24410.3364 |
| 18 | M 8 | 40 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 90 | 24410.3374 |
| 18 | M 8 | 50 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 82 | 24410.3384 |
| 18 | M 8 | 63 | 13,5 | 6,1+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 3,6 | 87 | 24410.3394 |
| 18 | M10 | 20 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 126 | 24410.3444 |
| 18 | M10 | 25 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 128 | 24410.3454 |
| 18 | M10 | 32 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 132 | 24410.3464 |
| 18 | M10 | 40 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 136 | 24410.3474 |
| 18 | M10 | 50 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 141 | 24410.3484 |
| 18 | M10 | 63 | 13,5 | 7,8+0,05 | 31,0 | 6,5 | 3 | 45 | 62 | 4,3 | 146 | 24410.3494 |

遵守

符合 RoHS

含鉛 - 相容除了例外 6a / 6b / 6c.

含有 >0.1% w/w 的 SVHC 物質

含鉛 - SVHC [REACH] 清單截至 2024 年 6 月 27 日

包含 65 號提案的物質



接觸鉛會導致癌症和生殖危害。接觸鎳會導致癌症。

<https://www.P65Warnings.ca.gov/>

不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈹、錫、金或鎢。