


星形把手 · DIN 6335 輕合金

EH 24630.

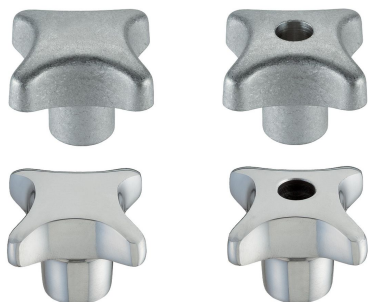

產品描述


這些手掌握把是根據 DIN 6335 製造的。

材質


把手

- 輕合金 (鋁), 未拋光或拋光


圖面

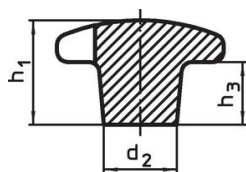



圖片 1

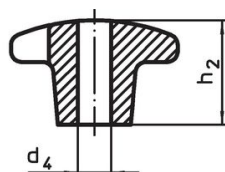


圖片 2

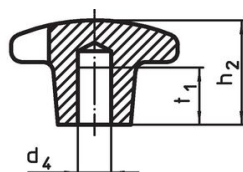

圖片 3

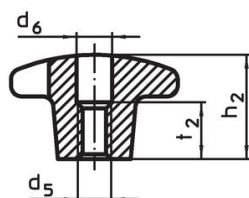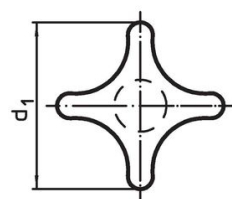

圖片 4

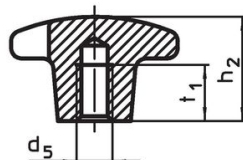


圖片 5

訂單資訊

d ₁	d ₂	d ₄ H7	d ₅	尺寸						[g]	品號	
				d ₆	h ₁	h ₂	h ₃	t ₁	t ₂			
[mm]												
未加工, 型式 A – 相片 1, 未拋光												
40	14	-	-	-	26	-	14	-	-	27	24630.0040	
50	18	-	-	-	34	-	20	-	-	51	24630.0050	
63	20	-	-	-	42	-	25	-	-	95	24630.0063	
80	25	-	-	-	52	-	30	-	-	161	24630.0080	
有平滑 盲孔, 型式 C – 相片 3, 未拋光												
40	14	8	-	-	-	25	-	15	-	23	24630.0240	
50	18	10	-	-	-	32	-	18	-	42	24630.0250	
63	20	12	-	-	-	40	-	22	-	73	24630.0263	
80	25	16	-	-	-	50	-	28	-	138	24630.0280	
有母牙 螺紋, 鑽孔, 型式 D – 相片 4, 未拋光												
40	14	-	M 8	8,4	-	25	-	-	13	23	24630.0340	
50	18	-	M10	10,5	-	32	-	-	16	44	24630.0350	
63	20	-	M12	13,0	-	40	-	-	20	70	24630.0363	
80	25	-	M16	17,0	-	50	-	-	20	129	24630.0380	
有盲孔, 母牙, 型式 E – 相片 5, 未拋光												
40	14	-	M 8	-	-	25	-	15	-	24	24630.0440	
50	18	-	M10	-	-	32	-	18	-	46	24630.0450	
63	20	-	M12	-	-	40	-	22	-	74	24630.0463	
80	25	-	M16	-	-	50	-	28	-	142	24630.0480	

d ₁	d ₂	d ₄ H7	d ₅	尺寸						[g]	品號
				d ₆	h ₁	h ₂	h ₃	t ₁	t ₂		
[mm]											
有平滑 盲孔， 型式 C – 相片 3, 已拋光											
40	14	8	–	–	–	25	–	15	–	23	24630.0640
50	18	10	–	–	–	32	–	18	–	42	24630.0650
63	20	12	–	–	–	40	–	22	–	73	24630.0663
80	25	16	–	–	–	50	–	28	–	138	24630.0680
有母牙 螺紋， 鑽孔， 型式 D – 相片 4, 已拋光											
40	14	–	M 8	8,4	–	25	–	–	13	23	24630.0740
50	18	–	M10	10,5	–	32	–	–	16	44	24630.0750
63	20	–	M12	13,0	–	40	–	–	20	70	24630.0763
80	25	–	M16	17,0	–	50	–	–	20	129	24630.0780
有盲孔， 母牙， 型式 E – 相片 5, 已拋光											
40	14	–	M 8	–	–	25	–	15	–	24	24630.0840
50	18	–	M10	–	–	32	–	18	–	46	24630.0850
63	20	–	M12	–	–	40	–	22	–	74	24630.0863
80	25	–	M16	–	–	50	–	28	–	142	24630.0880

應用範例

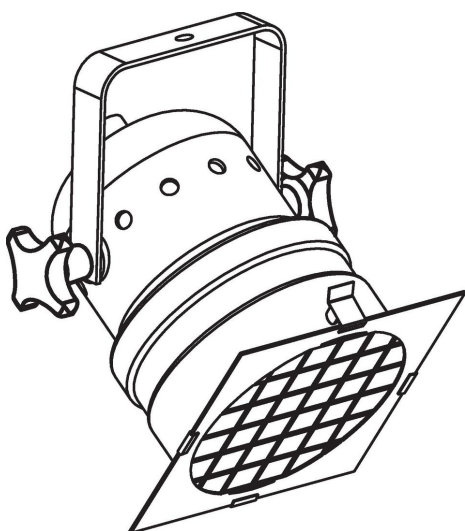

遵守

有關詳細的合規信息，請選擇所需的貨號。