

絞鏈

EH 25165.



產品描述

The different versions cover many applications that require a low load. These metal hinges are characterised by their simple design and the different versions:

- without bores
- with bores
- with bores for countersunk screws

The version without bores can be assembled by welding or by inserting a specific drilling pattern.

材質


本體

- 不銹鋼 1.4301
- 鋼，鍍鋅，鈍化

軸

- 不銹鋼 1.4301


圖面

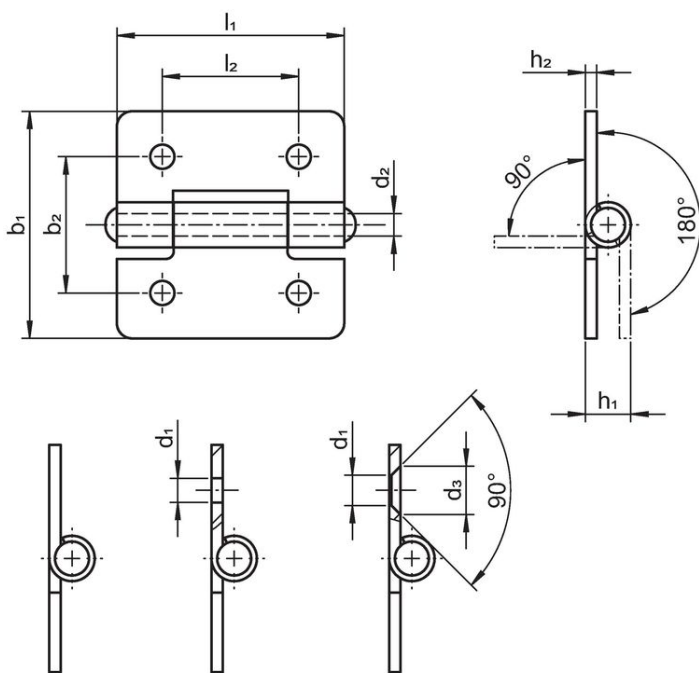

picture 1

picture 2

picture 3

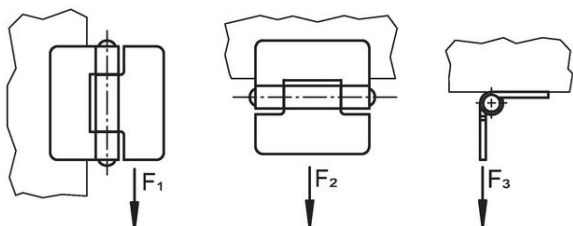

訂單資訊

b <sub>1</sub>	l <sub>1</sub>	b <sub>2</sub>	d <sub>1</sub>	尺寸					夾持力			[g]	品號	
				d <sub>2</sub>	d <sub>3</sub>	h <sub>1</sub> ~	h <sub>2</sub>	l <sub>2</sub>	F <sub>1</sub> ~	F <sub>2</sub> ~ [N]	F <sub>3</sub> ~			
without bores – 相片 1, 不銹鋼														
30	30	–	–	3	–	6	1,5	–	700	500	500	15	<a href="#">25165.0015</a>	
40	40	–	–	4	–	8	2,0	–	2000	1000	1000	34	<a href="#">25165.0025</a>	
50	50	–	–	6	–	10	2,0	–	2500	2000	1000	62	<a href="#">25165.0040</a>	
60	60	–	–	6	–	10	2,0	–	2800	2500	1000	83	<a href="#">25165.0060</a>	
with bores – 相片 2, 不銹鋼														
30	30	18	3,2	3	–	6	1,5	18	700	500	500	15	<a href="#">25165.0115</a>	
40	40	25	4,2	4	–	8	2,0	25	2000	1000	1000	33	<a href="#">25165.0125</a>	
50	50	30	3,2	6	–	10	2,0	30	2500	2000	1000	61	<a href="#">25165.0140</a>	
60	60	36	5,2	6	–	10	2,0	36	2800	2500	1000	80	<a href="#">25165.0160</a>	
with bores – 相片 2, 鋼														
30	30	18	3,2	3	–	6	1,5	18	700	500	500	15	<a href="#">25165.1015</a>	
40	40	25	4,2	4	–	8	2,0	25	2000	1000	1000	33	<a href="#">25165.1025</a>	
50	50	30	5,2	6	–	10	2,0	30	2500	2000	1000	61	<a href="#">25165.1040</a>	
60	60	36	5,2	6	–	10	2,0	36	2800	2500	1000	80	<a href="#">25165.1060</a>	
with bores for countersunk screws – 相片 3, 不銹鋼														
30	30	18	4,0	3	6,4	6	1,5	18	700	500	500	15	<a href="#">25165.0215</a>	
40	40	25	4,0	5	8,3	8	2,0	25	2000	1000	1000	33	<a href="#">25165.0225</a>	
50	50	30	4,0	6	8,3	10	2,0	30	2500	2000	1000	61	<a href="#">25165.0240</a>	
60	60	36	5,0	6	8,3	10	2,0	36	2800	2500	1000	80	<a href="#">25165.0260</a>	
with bores for countersunk screws – 相片 3, 鋼														
30	30	18	4,0	3	6,4	6	1,5	18	700	500	500	15	<a href="#">25165.2015</a>	
40	40	25	5,0	4	8,3	8	2,0	25	2000	1000	1000	33	<a href="#">25165.2025</a>	
50	50	30	5,0	6	8,3	10	2,0	30	2500	2000	1000	61	<a href="#">25165.2040</a>	
60	60	36	5,0	6	8,3	10	2,0	36	2800	2500	1000	80	<a href="#">25165.2060</a>	

遵守

符合 RoHS

符合指令 2011/65/EU 和指令 2015/863

不含 SVHC 物質

不含超過 0.1% w/w 的 SVHC 物質 - 截至 2024 年 1 月 23 日的 SVHC 清單。

不含 65 號提案物質

不包括 65 號提案物質

<https://www.P65Warnings.ca.gov/>

不含衝突礦物

本產品不含來自剛果民主共和國或鄰近國家的任何被指定為“衝突礦物”的物質，例如鈿、錫、金或鎢。